
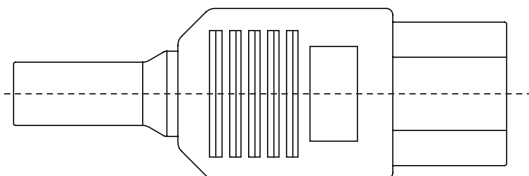
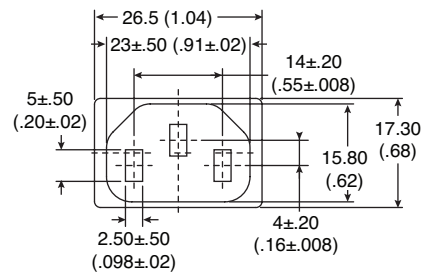
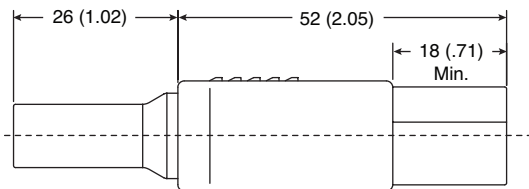
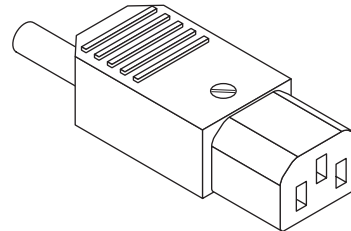


Cable Connector Outlet

161-R332-E

KOBI CONN

Cable Connector Outlet

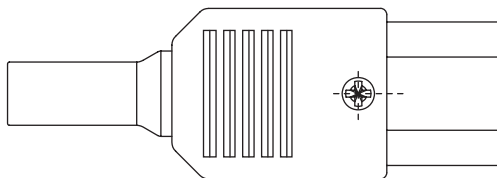

Dimensions: mm (In.)

SPECIFICATIONS

Rating:	10A, 250VAC
Insulation Resistance:	Over 100MΩ at 500VDC
Dielectric Strength:	2000VAC for 1 Minute

MATERIALS

Body:	Black Glass-Filled Thermoplastic
RoHS Compliant	

Tolerance

X.XX±0.1
XX.XX±0.2
XXX.XX±0.3

Date Last Revised: 1-30-07

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC- 301087

161-R332-E

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[161-R332-E](#)