


**Dimensions: mm (In.)**

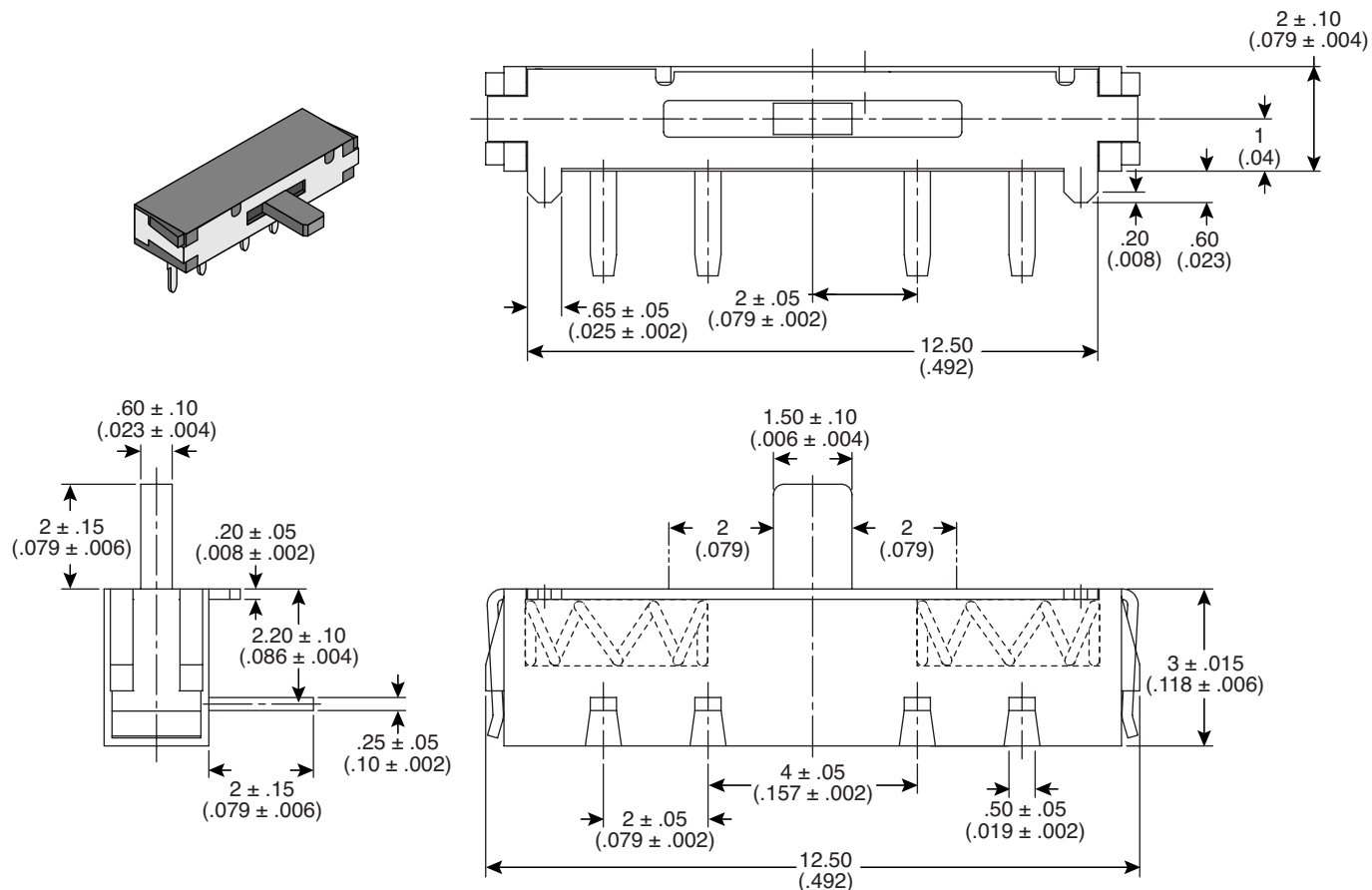

### Electrical Specifications:

- Rating: Non-Switching-100mA/50VDC  
Switching-25mA/24VDC
- Contact Resistance: 100mΩ max.
- Insulation Resistance: 100MΩ min.
- Dielectric Strength: 500VAC for 1 min.

### Mechanical Specifications:

- Operating Temperature: -20°C~+70°C
- Storage Temperature: -40°C~+85°C

**Note:**

- RoHS Compliant and Process Compatible with 260° Solder

Slide Switch  
103-5030-EV

# Mountain Switch

Available from Mouser Electronics

www.mouser.com

1-800-346-6873

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[103-5030-EV](#)