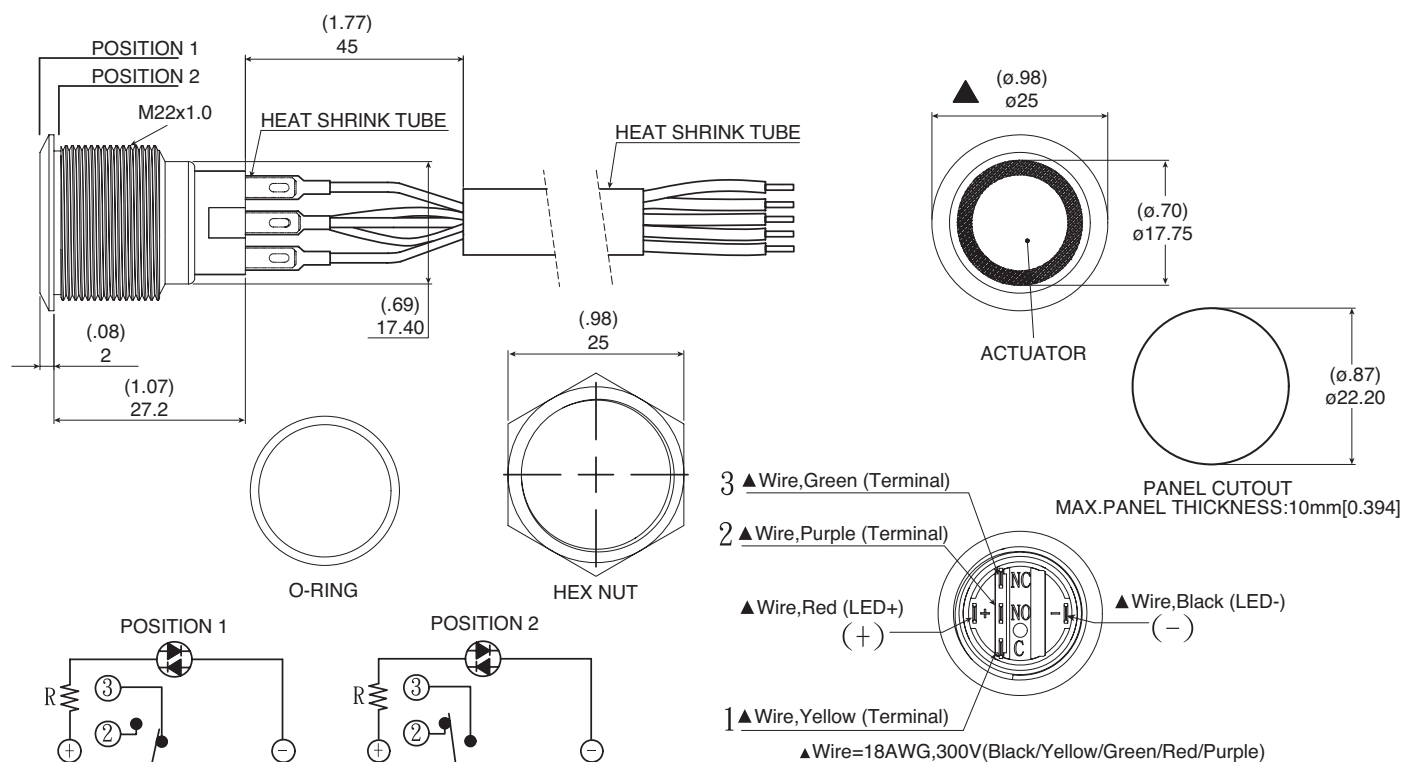


Dimensions: mm (in.)

**Mechanical Specifications:**

- Life: Self-Lock 500,000
- Operating Temperature: -20°C to 55°C
- LED Color: Red

Material:

- Body Type & Color: Stainless Steel, Natural SUS

Electrical Specifications:

- Rating: 5A/250VAC. resistive load 3A/250VAC.
- Life: 50,000 Make-and Break Cycles at Full Load
- Insulation Resistance: 1,000MΩ Min. at 500VDC.
- Dielectric Strength: 2,000V RMS@sea level.
- Contact Resistance: 50mΩ Max. @1A 12VDC (initial value)
- LED Voltage: 24V

Note:

- RoHS Compliant by Exemption

Illuminated Pushbutton Switch
108-22243-EVX

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[108-22243-EVX](#)