



Mallory Sonalert Products, Inc.

Part #:

ZT028LACTR30

Sales Outline Drawing

Revision:

C



Specifications:

Sound Level Category	Loud
Sound Operation	Continuous for 30 Seconds, then Silence until reset.
Lens Color	Opaque White
LED Color	RED
LED Operation	Continuous then flash at .1s on .9s off
Voltage Rating	20 to 28 VAC/DC
Frequency	3900 $\pm$ 500 Hz
Loudness @ 2 FT	85 to 95 dB(A) Typ.
Current Draw	40mA MAX
Housing Material	6/6 Nylon, Color: Black
Front Cap Material	6/6 Nylon, Color: Opaque White
Storage Temperature	-40° to +80° C
Operating Temperature	-30° to +65° C
Panel Mounting	Recommended hole size is 22.5 mm. Thread front will fit standard 22.5mm hole.
Knurled Nut	Used to attach part to panel. The max recommended torque is 10 in-lbs.
Weight (Typical)	28 g
NEMA 3R,4X, & 12	Approved with use of included gasket.
Options	Please contact factory.

Dimensions: Inches (mm)

cUL Recognized

ROHS Compliant

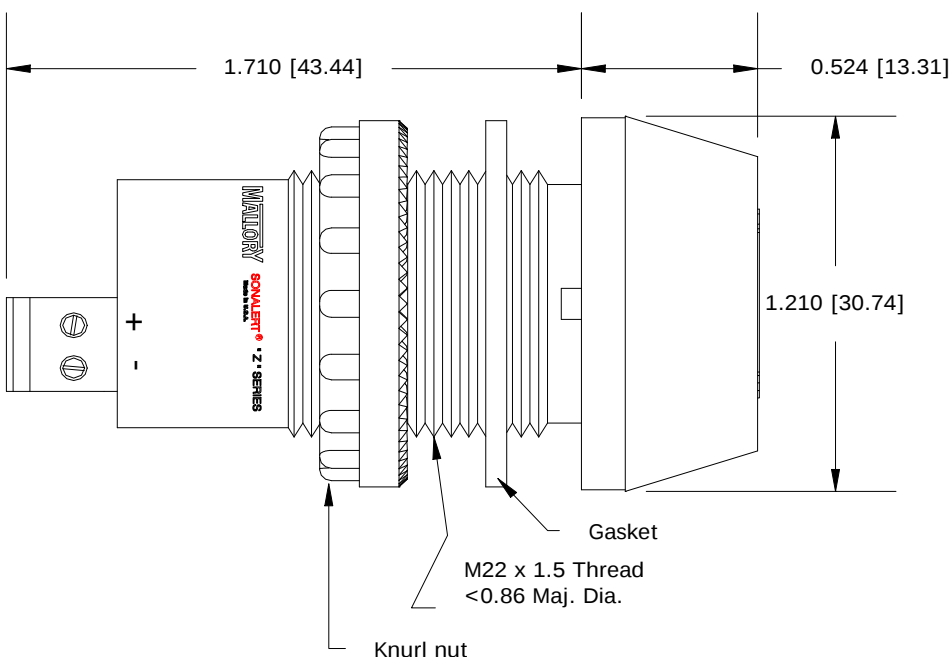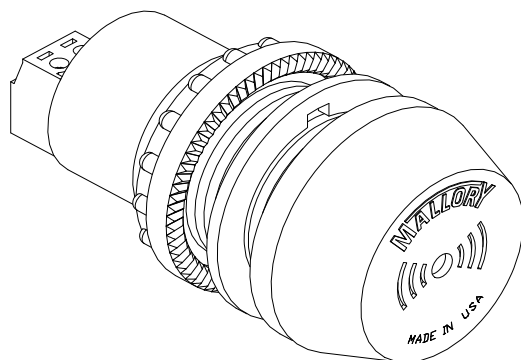

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[ZT028LACTR30](#)