

Main

Range of product	Harmony Series K
Product or component type	Cam switch operating head
Component name	KAX
Product compatibility	Front mounting bodies 12 and 20 A by Ø 22 mm hole
Cam switch head type	With bezel Ø 28.5 mm, metal
Type of operator	Key Ronis 455
Rotary handle padlocking	Without
Presentation of legend	With mat black legend
Switching angle	45 °

Complementary


Mechanical durability	1000000 cycles
CAD overall width	29 mm
CAD overall height	29 mm
CAD overall depth	21 mm
Product weight	0.065 kg

Environment

Protective treatment	TC
Ambient air temperature for operation	-25...55 °C
Ambient air temperature for storage	-40...70 °C
Shock resistance	30 gn conforming to IEC 68-2-27
Vibration resistance	5 gn, 10...150 Hz conforming to IEC 68-2-6
IP degree of protection	IP65 conforming to NF C 20-010 IP65 conforming to IEC 529


Operating Head

For Ø 22 mm/0.87 in. Hole, Front Mounting Body

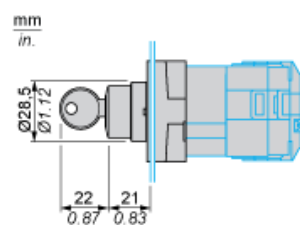

Operating Head

 Panel Cut-out



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[KAXZ1S141](#)