


Main

Range of product	Advantys Telefast ABE7
Product or component type	Plug-in solid state relay
Relay type	Output relay
Quantity per set	Set of 4

Complementary

Response time	<= 0.2 ms from state 0 to 1 <= 0.1 ms from state 1 to 0
Width pitch dimension	12 mm
Product compatibility	ABE7P16T318 ABE7P16T318E ABE7P16T330 ABE7P16T330E ABE7P16T334 ABE7R16T330 ABE7R16T332
Discrete input voltage	24 V DC
Discrete output voltage	24 V DC self-protected output(s)
Discrete output current	2000 mA
Current state 0 guaranteed	0.4 mA DC
Current state 1 guaranteed	2.9 mA DC
Voltage state 0 guaranteed	3.8 V DC
Voltage state1 guaranteed	18.6 V DC
Product weight	0.016 kg

Internal Wiring Diagram

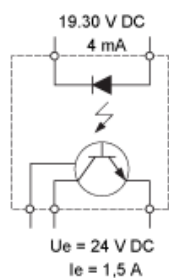

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[ABS7SC3BA](#)