





DB UNLIMITED

Part Number:	DRAWN	8/10/2016
	CJ	
	CHECKED	8/10/2016
Description:	P.D.	J.S.
	APPROVED	8/10/2016
Dynamic Speaker		
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Top View

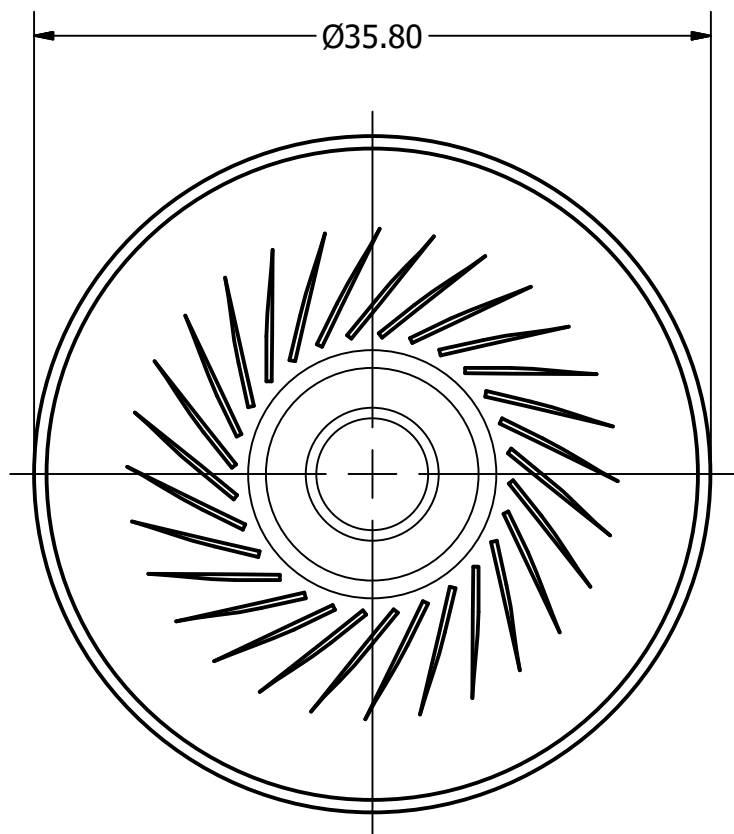

Side View

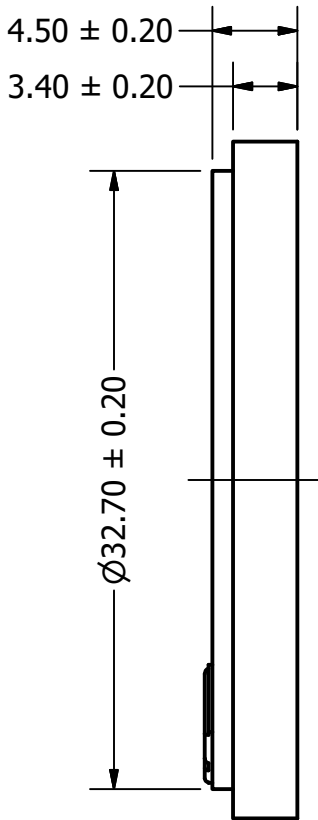

Bottom View

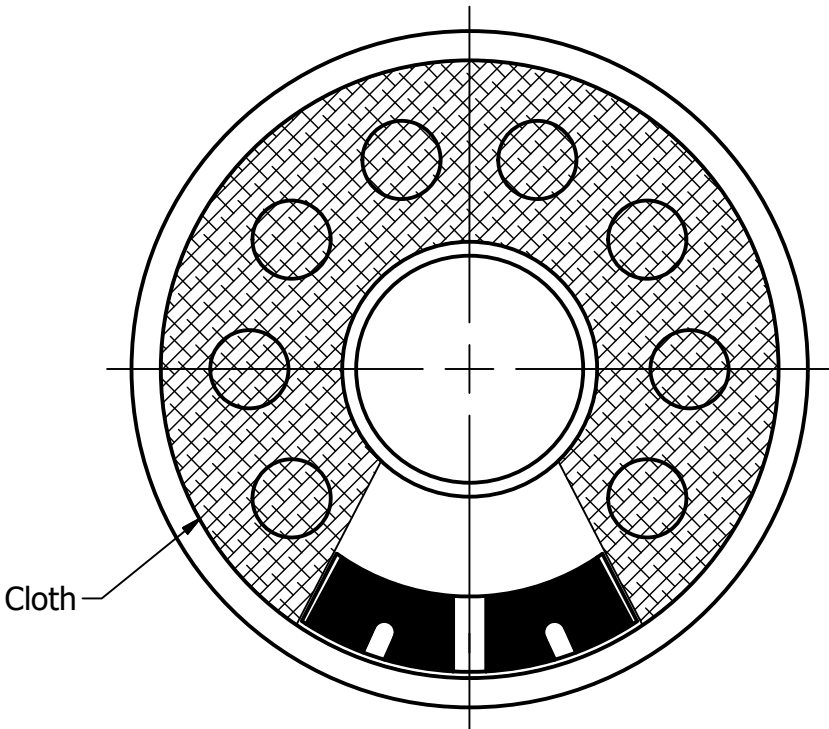

Items		Specifications	Conditions	REVISION HISTORY		
				REV	DESCRIPTION	DATE
Sound Pressure Level		89	dB (@ 10cm)		Released from Engineering	10/21/2013
Resonant Frequency		500	Hz			J.S.
Frequency Range		500 ~ 5,000	Hz	1	Updated to new template	8/10/2016
Nominal Power		0.5	W	2	Corrected SPL, resonant frequency,frequency range, operating temp, storage temp, and weight	5/17/2017
Max. Power		1	W			
Impedance		8	Ω			C.E.
Cone Material		Mylar		NOTES		
Mount Type		Flush Mount		1) All dimensions are in mm unless otherwise noted		
Storage Temperature		-25 ~ +60	°C	2) All tolerances are ± 0.5 mm unless otherwise noted		
Operating Temperature		-25 ~ +60	°C	3) All parts meet RoHS		
Weight		8.5	g	4) Subject to change or redrawn without notice		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SM350508-1](#)