




TOP VIEW

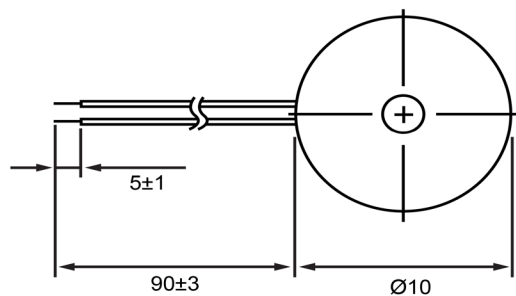

SIDE VIEW

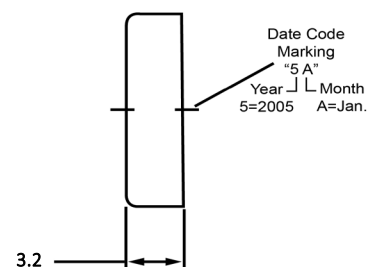

Specifications			Notes	Revision History													
Description	Value	Unit		Version	Description		Date	Approved									
Technology	Piezo		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S									
Resonant Frequency	3,200	(Hz)															
Rated Voltage	10	(V)															
SPL @ 10cm	80	(dBA)															
Capacitance	11,000	(pF)															
Mount Type	Flush																
Voltage Range	1 ~ 30	(V)															
Max Rated Current	7	(mA)															
Housing Material	ABS																
Operating Temperature	-20 ~ +70	°C															
Storage Temperature	-20 ~ +60	°C															
Weight	1	(g)															
 DB UNLIMITED						Drawn by		Date		Checked by		Date		Approved by		Date	
			Piezo Transducer			TP103210-1											

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP103210-1](#)