

## Customer Part:

### Description

- Industry standard leaded package  
Resistance welded, hermetically sealed in an inert atmosphere, glass to metal seals on leads
- Standard 2 leg HC49 package
- Model HC49
- Model Issue number 15

### Frequency Parameters

- Frequency 12.2880MHz
- Frequency Tolerance  $\pm 30.00\text{ppm}$
- Frequency Stability  $\pm 50.00\text{ppm}$
- Operating Temperature Range  $-10.00$  to  $60.00^\circ\text{C}$
- Overtone Order Fundamental
- Ageing  $\pm 3\text{ppm}$  typical per year

### Electrical Parameters

- Load Capacitance Series Resonant
- Shunt Capacitance  $7\text{pF}$  max
- Drive Level  $1\text{mW}$  max
- ESR  $35.00\Omega$  max

### Environmental Parameters


- Shock:  $981\text{m/s}^2$ , 6ms, 3 times in each of 3 mutually perpendicular planes
- Vibration: 10Hz-60Hz, 0.75mm amplitude, 60Hz-500Hz,  $98.1\text{m/s}^2$ , 30mins in 3 mutually perpendicular planes
- Storage Temperature Range:  $-55$  to  $125^\circ\text{C}$

### Compliance

- RoHS Status (2015/863/EU) Compliant
- REACH Status Compliant
- MSL Rating (JDEC-STD-033): Not Applicable

### Packaging Details

- Pack Style: Bulk Loose in bulk pack  
Pack Size: 100
- *Alternative packing option available*

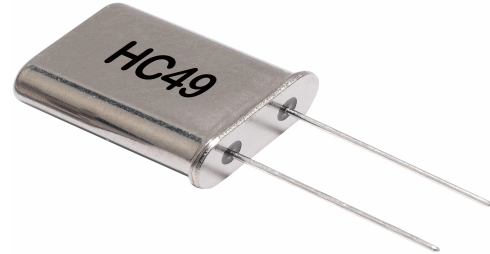

### Outline (mm)



## Sales Office Contact Details:

UK: +44 (0)1460 270200  
Germany: 0800 1808 443

France: 0800 901 383  
USA: +1.760.318.2824

Email: [info@iqdfrequencyproducts.com](mailto:info@iqdfrequencyproducts.com)  
Web: [www.iqdfrequencyproducts.com](http://www.iqdfrequencyproducts.com)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[IQD Frequency Products:](#)

[LFX TAL022947Bulk](#)