


British Plug Top Fuse

Fast-Acting

TDC600



Dimensional Data

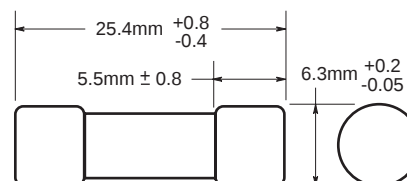

Catalog Symbol: TDC600

Fast-Acting, High Breaking Capacity Fuse

600 Volts AC

BS1362, UL Recognized

Electrical Ratings (Catalog Symbol and Amperes)

600 Volts

TDC600-2A

TDC600-10A


Rated Current	Rated Voltage (V)	Breaking Capacity	Power Dissipation (W)	Color	Approvals
2A 10A	600	200A, 600V 10kA, 250V p.f. 0.7 - 0.8	1 Watt @ Rated Current	Blue	Asta, BSI

- **Type TDC600.**
- 1/4" x 1" fast-acting, high breaking capacity fuse.
- Ceramic tube - end caps: silver-plated copper.
- Packaging: x 10, x 100, x 1000.
- Weight: 2.5g.

Limits for Pre-arcing Time

	1.0 In.	1.6 In.	1.9 In.
In	MIN	MIN	MAX
2A, 10A	1000 hours	30 min.	30 min.

Time-Current Characteristic Curves Average Melt (Full Size Curves Available)

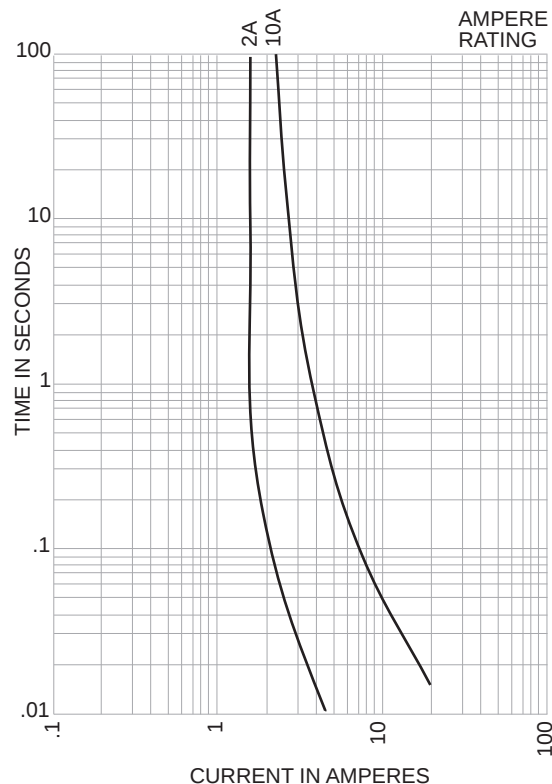

The only controlled copy of this Data Sheet is the electronic read-only version located on the Bussmann Network Drive. All other copies of this Data Sheet is are by definition uncontrolled. This bulletin is intended to clearly present comprehensive product data and provide technical information that will help the end user with design applications. Bussmann reserves the right, without notice, to change design or construction of any products and to discontinue or limit distribution of any products. Bussmann also reserves the right to change or update, without notice, any technical information contained in this bulletin. Once a product has been selected, it should be tested by the user in all possible applications.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eaton:

[BK/TDC600-10A](#) [BK/TDC600-2A](#)