


CORNELL DUBILIER 径向射频云母电容器

CDE CORNELL DUBILIER

CDE CORNELL DUBILIER 径向引线浸胶云母高电压射频电容器

独有的 CDE 浸胶工艺, 提供出色的防潮性能。符合 EIA 规范。

- 容差: D=0.5pF, J=5%
- 温度范围: -55°C 至 +125°C
- 电压范围: 100, 300, 500 和 1000VDC
- 振动测试: 10-2000Hz
- 脉冲处理: 20,000V/μs 的 dV/dt

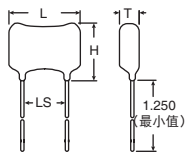

尺寸: in.



引脚间距: in.			
CD5	CD10	CD15	CD19
.120	.141	.234	.344

CD5 系列

订购 500 只及以上者, 请来电询价。

贸泽电子料号	CDE 料号	电压 (直流)	容值 (pF)	尺寸: in. 最大值			单价		
				L	H	T	1	25	100
598-CD5CC010DO3F	CD5CC010DO3F	300	1	.270	.190	.110	16.91	14.30	9.09
598-CD5CC030DO3F	CD5CC030DO3F	300	3	.270	.190	.110	16.91	14.30	9.09
598-CD5CC050DO3F	CD5CC050DO3F	300	5	.270	.190	.110	20.56	17.36	11.03
598-CD5CC100DO3F	CD5CC100DO3F	300	10	.270	.190	.110	11.70	9.91	6.42
598-CD5CC120JO3F	CD5CC120JO3F	300	12	.270	.190	.110	9.83	8.34	5.41
598-5-300V15-F	CD5CC150JO3F	300	15	.270	.190	.110	8.49	6.78	5.46
598-CD5CC180JO3F	CD5CC180JO3F	300	18	.270	.200	.120	10.36	8.72	5.62
598-CD5EC200JO3F	CD5EC200JO3F	300	20	.270	.200	.120	10.36	8.79	5.62
598-CD5EC220JO3F	CD5EC220JO3F	300	22	.270	.200	.120	10.80	9.09	5.83
598-CD5EC270JO3F	CD5EC270JO3F	300	27	.270	.200	.130	10.36	8.87	5.60
598-CD5EC300JO3F	CD5EC300JO3F	300	30	.270	.200	.130	11.47	9.76	6.24
598-CD5EC330JO3F	CD5EC330JO3F	300	33	.270	.200	.130	11.99	10.06	6.47
598-CD5EC390GO3F	CD5EC390GO3F	300	39	.270	.210	.130	35.54	30.10	19.15
598-CD5EC390JO3F	CD5EC390JO3F	300	39	.270	.210	.130	23.24	19.67	12.52
598-CD5EC470JO3F	CD5EC470JO3F	300	47	.270	.210	.140	13.41	11.25	7.17
598-CD5EC510JO3F	CD5EC510JO3F	300	51	.270	.210	.140	20.86	17.73	11.18
598-CD5EC680JO3F	CD5EC680JO3F	300	68	.270	.220	.150	19.15	16.17	10.21
598-CD5EC750JO3F	CD5EC750JO3F	300	75	.270	.230	.160	16.84	14.23	9.04
598-CD5FC101JO3F	CD5FC101JO3F	300	100	.270	.240	.180	24.21	20.49	13.01

CD10 系列

订购 500 只及以上者, 请来电询价。

贸泽电子料号	CDE 料号	电压 (直流)	容值 (pF)	尺寸: in. 最大值			单价		
				L	H	T	1	25	100
598-CD10CD050DO3F	CD10CD050DO3F	500	5	.360	.330	.190	16.09	12.37	10.43
598-CD10CD100DO3F	CD10CD100DO3F	500	10	.360	.330	.190	16.99	13.04	11.03
598-CD10CD120JO3F	CD10CD120JO3F	500	12	.360	.330	.190	11.25	8.64	8.05
598-CD10CD150JO3F	CD10CD150JO3F	500	15	.360	.330	.190	16.91	13.04	10.95
598-CD10CD180JO3F	CD10CD180JO3F	500	18	.360	.330	.190	16.99	13.04	11.03
598-CD10ED200JO3F	CD10ED200JO3F	500	20	.360	.330	.190	12.81	9.83	8.42
598-CD10ED220JO3F	CD10ED220JO3F	500	22	.360	.330	.190	12.81	9.83	8.42
598-CD10ED240JO3F	CD10ED240JO3F	500	24	.360	.330	.190	12.81	9.83	8.42
598-CD10ED270JO3F	CD10ED270JO3F	500	27	.370	.330	.190	12.81	9.83	8.42
598-CD10ED300JO3F	CD10ED300JO3F	500	30	.370	.340	.190	8.27	6.40	5.96
598-CD10ED330JO3F	CD10ED330JO3F	500	33	.370	.340	.190	12.81	9.91	8.49
598-CD10ED360JO3F	CD10ED360JO3F	500	36	.370	.340	.190	14.60	11.25	9.54
598-CD10ED390JO3F	CD10ED390JO3F	500	39	.370	.340	.190	14.45	11.25	9.46
598-CD10ED470JO3F	CD10ED470JO3F	500	47	.370	.340	.190	14.97	11.62	9.83
598-CD10ED500JO3F	CD10ED500JO3F	500	50	.370	.340	.190	14.90	11.55	10.88
598-CD10ED560JO3F	CD10ED560JO3F	500	56	.370	.340	.190	9.69	7.52	7.15
598-CD10ED820JO3F	CD10ED820JO3F	500	82	.370	.350	.200	15.65	12.14	10.21
598-CD10FD101JO3F	CD10FD101JO3F	500	100	.370	.350	.200	15.65	12.14	10.21
598-CD10FD121JO3F	CD10FD121JO3F	500	120	.380	.350	.200	10.36	8.05	7.45
598-CD10FD151FO3F	CD10FD151FO3F	500	150	.380	.360	.210	29.43	22.80	19.15
598-CD10FD151JO3F	CD10FD151JO3F	500	150	.380	.360	.210	10.58	8.20	7.75
598-CD10FD181JO3F	CD10FD181JO3F	500	180	.390	.370	.210	19.22	14.75	12.52
598-CD10FD201JO3F	CD10FD201JO3F	500	200	.390	.370	.210	32.48	25.11	21.23
598-CD10FD221JO3F	CD10FD221JO3F	500	220	.390	.380	.220	22.28	17.14	14.53

CD15 系列

订购 500 只及以上者, 请来电询价。

贸泽电子料号	CDE 料号	电压 (直流)	容值 (pF)	尺寸: in. 最大值			单价		
				L	H	T	1	25	100
598-CD15FA112JO3F	CD15FA112JO3F	100	1100	.490	.420	.240	30.62	23.77	20.19
598-CD15FA102JO3F	CD15FA102JO3F	100	1000	.480	.400	.230	28.46	21.90	18.77
598-CD15FC621JO3F	CD15FC621JO3F	300	620	.460	.380	.210	23.62	18.25	15.42
598-CD15FC681FO3F	CD15FC681FO3F	300	680	.470	.390	.210	29.20	22.57	19.07
598-CD15FC751JO3F	CD15FC751JO3F	300	750	.470	.390	.210	28.38	21.90	18.55
598-CD15FC561JO3F	CD15FC561JO3F	300	560	.460	.380	.210	22.05	16.99	14.38
598-CD15FC681JO3F	CD15FC681JO3F	300	680	.470	.390	.210	26.67	20.64	17.36
598-CD15FC821JO3F	CD15FC821JO3F	300	820	.470	.390	.210	30.77	23.77	20.26
598-CD15CD120JO3F	CD15CD120JO3F	500	12	.360	.330	.190	8.34	6.33	5.48
598-CD15CD180JO3F	CD15CD180JO3F	500	18	.450	.360	.170	8.27	6.33	5.46
598-CD15ED240JO3F	CD15ED240JO3F	500	24	.450	.360	.170	5.89	4.54	4.24
598-CD15ED510JO3F	CD15ED510JO3F	500	51	.450	.360	.170	5.74	4.40	3.81
598-CD15ED620JO3F	CD15ED620JO3F	500	62	.450	.360	.170	8.72	6.78	5.79
598-CD15ED750JO3F	CD15ED750JO3F	500	75	.450	.360	.180	8.72	6.78	5.79
598-CD15FD111JO3F	CD15FD111JO3F	500	110	.460	.370	.180	8.87	6.78	5.48
598-CD15FD431JO3F	CD15FD431JO3F	500	430	.470	.390	.210	29.06	22.42	18.92
598-CD15CD050DO3F	CD15CD050DO3F	500	5	.450	.360	.170	5.89	4.54	4.17
598-CD15CD100JO3F	CD15CD100JO3F	500	10	.450	.360	.170	8.72	6.71	5.74

CD15 系列 (续)

订购 500 只及以上者, 请来电询价。

贸泽电子料号	CDE 料号	电压 (直流)	容值 (pF)	尺寸: in. 最大值			单价		
				L	H	T	1	25	100
598-CD15CD100DO3F	CD15CD100DO3F	500	10	.450	.360	.170	5.89	4.54	4.24
598-CD15CD150JO3F	CD15CD150JO3F	500	15	.450	.360	.170	8.34	6.33	5.48
598-15-500V20F	CD15ED200JO3F	500	20	.450	.360	.170	5.66	4.99	3.87
598-CD15ED220JO3F	CD15ED220JO3F	500	22	.450	.360	.170	5.89	4.54	3.87
598-CD15ED270JO3F	CD15ED270JO3F	500	27	.450	.360	.170	5.89	4.54	3.87
598-CD15ED300JO3F	CD15ED300JO3F	500	30	.450	.360	.170	8.49	6.56	5.60
598-CD15ED330JO3F	CD15ED330JO3F	500	33	.450	.360	.170	5.89	4.54	3.87
598-CD15ED390JO3F	CD15ED390JO3F	500	39	.450	.360	.170	8.49	6.56	5.60
598-CD15ED470JO3F	CD15ED470JO3F	500	47	.450	.360	.170	5.74	4.40	3.81
598-CD15ED500JO3F	CD15ED500JO3F	500	50	.450	.360	.170	8.34	6.48	5.57
598-CD15ED560JO3F	CD15ED560JO3F	500	56	.450	.360	.170	8.34	6.48	5.57
598-CD15ED680JO3F	CD15ED680JO3F	500	68	.450	.360	.180	9.01	7.06	6.06
598-15-500V82-F	CD15ED820JO3F	500	82	.450	.360	.180	8.72	6.78	5.79
598-CD15FD101JO3F	CD15FD101JO3F	500	100	.460	.360	.180	5.89	4.54	3.91
598-CD15FD121JO3F	CD15FD121JO3F	500	120	.460	.370	.180	9.61	7.45	6.33
598-CD15FD151JO3F	CD15FD151JO3F	500	150	.460	.370	.190	6.93	5.36	4.52
598-CD15FD181JO3F	CD15FD181JO3F	500	180	.460	.370	.190	11.10	8.57	7.26
598-CD15FD201JO3F	CD15FD201JO3F	500	200	.460	.380	.190	7.97	6.18	5.51
598-CD15FD221JO3F	CD15FD221JO3F	500	220	.460	.380	.200	8.34	6.48	5.50
598-CD15FD241JO3F	CD15FD241JO3F	500	240	.460	.380	.200	12.96	10.06	8.49
598-CD15FD251JO3F	CD15FD251JO3F	500	250	.470	.390	.210	12.22	9.46	7.97
598-CD15FD271JO3F	CD15FD271JO3F	500	270	.470	.390	.210	14.08	10.80	9.31
598-15-500V300-F	CD15FD301JO3F	500	300	.470	.390	.210	15.27	11.85	9.98
598-CD15FD331JO3F	CD15FD331JO3F	500	330	.470	.390	.210	20.49	14.90	12.67
598-CD15FD361JO3F	CD15FD361JO3F	500	360	.470	.390	.210	12.29	9.46	8.20
598-CD15FD391JO3F	CD15FD391JO3F	500	390	.470	.390	.210	12.29	9.46	8.05
598-CD15FD471JO3F	CD15FD471JO3F	500	470	.470	.400	.220	23.54	17.36	14.75
598-CD15FD501JO3F	CD15FD501JO3F	500	500	.470	.400	.220	14.53	11.18	9.46
598-CD15FD511JO3F	CD15FD511JO3F	500	510	.470	.400	.220	22.20	17.06	14.53

CD19 系列

订购 500 只及以上者, 请来电询价。

贸泽电子料号	CDE 料号	电压 (直流)	容值 (pF)	尺寸: in. 最大值			单价		
				L	H	T	1	25	100
598-CD19FD271JO3F	CD19FD271JO3F	500	270	.640	.500	.190	13.41	11.40	7.11
598-CD19FD331JO3F	CD19FD331JO3F	500	330	.640	.500	.190	16.91	14.16	9.09
598-CD19FD391JO3F	CD19FD391JO3F	500	390	.640	.510	.200	20.93	17.73	11.32
598-CD19FD471JO3F	CD19FD471JO3F	500	470	.640	.510	.200	17.88	15.05	9.46
598-CD19FD501JO3F	CD19FD501JO3F	500	500	.640	.510	.200	17.88	15.05	9.46
598-CD19FD511JO3F	CD19FD511JO3F	500	510	.650	.510	.200	14.60	12.29	9.67
598-CD19FD561JO3F	CD19FD561JO3F	500	56						