



OA119AP All Metal Series



AC Fans - 115, 230V
127mm x 38mm (5.0" x 1.5")

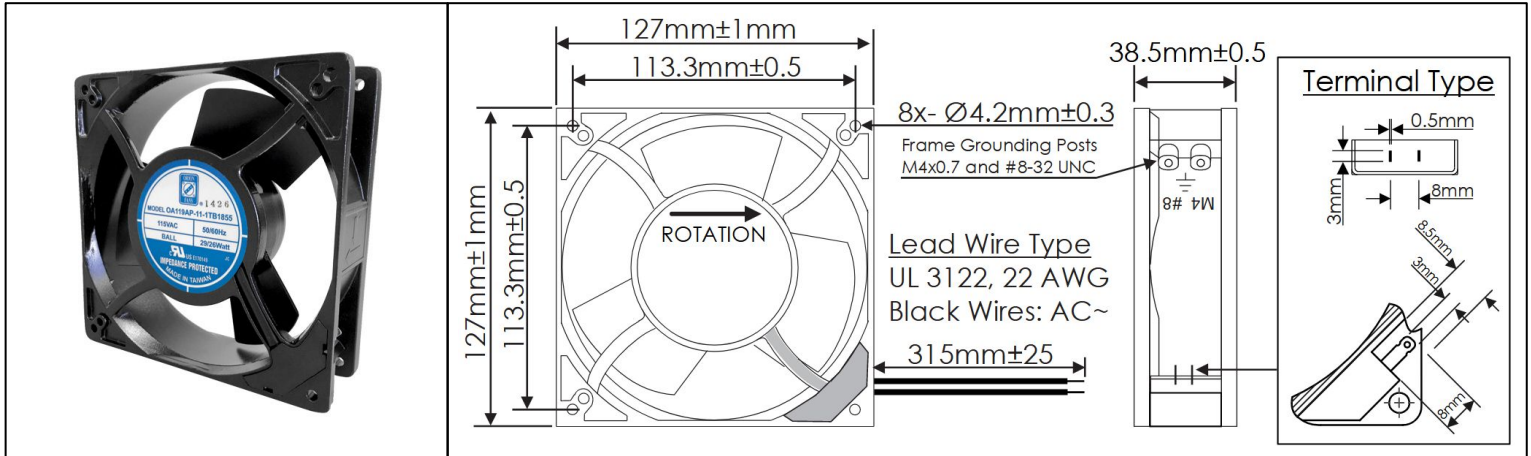

Frame	Die Cast Aluminum, Black Finish	Operating Temperature -30°C ~ +80°C Storage Temperature -40°C ~ +100°C Life Expectancy 50,000 Hours (L10 at 55°C) Installed Options IP55 Rated Motor Available Options Salt Fog Ratings Other Voltages Weight: 1.4 lbs.
Impeller	Steel Alloy, Black Finish	
Power Connection	2x Lead Wires, UL 3122 22 AWG 315mm, or Terminals	
Motor	AC Shaded Pole, Single Phase, Impedance Protected, IP55 Rated	
Bearing System	Dual Ball Bearings	
Dielectric Strength	1500VAC/min, <1mA	
Insulation Resistance	≥10MΩ @ 500V DC	

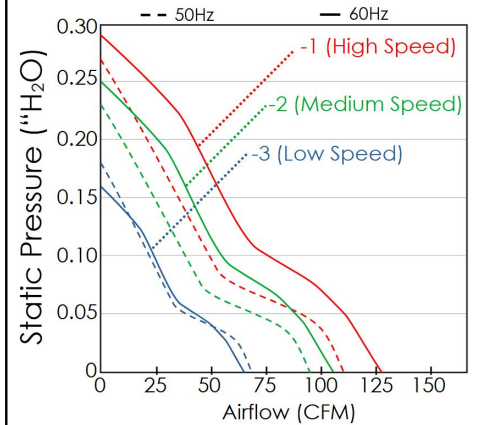

Part Number	Rated Voltage (Volts AC)	Voltage Range (Volts AC)	Frequency (Hertz)	Rated Power (Watts)	Rated Speed (RPM)	Max Airflow (CFM)	Noise Level (dBA)	Max Static Pressure ("H ₂ O)
OA119AP-11-1*B1855	115	100 ~ 125	50 / 60	29 / 26	2600 / 2950	110 / 128	48	0.27 / 0.29
OA119AP-11-2*B1855	115	100 ~ 125	50 / 60	23 / 20	2300 / 2400	95 / 105	42	0.23 / 0.25
OA119AP-11-3*B1855	115	100 ~ 125	50 / 60	18 / 15	1600 / 1500	68 / 65	28	0.18 / 0.16
OA119AP-22-1*B1855	230	200 ~ 250	50 / 60	29 / 26	2600 / 2950	110 / 128	48	0.27 / 0.29
OA119AP-22-2*B1855	230	200 ~ 250	50 / 60	23 / 20	2300 / 2400	95 / 105	42	0.23 / 0.25
OA119AP-22-3*B1855	230	200 ~ 250	50 / 60	18 / 15	1600 / 1500	68 / 65	28	0.18 / 0.16

* Insert "T" for Terminal type power connection, or "W" for Wire Lead type power connection.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Orion Fans:](#)

[OA119AP-22-1TB1855](#) [OA119AP-11-1TB1855](#) [OA119AP-22-1WB1855](#) [OA119AP-11-1WB1855](#) [OA119AP-22-2TB1855](#) [OA119AP-11-2TB1855](#) [OA119AP-22-2WB1855](#) [OA119AP-11-2WB1855](#) [OA119AP-22-3WB1855](#)
[OA119AP-11-3TB1855](#) [OA119AP-22-3TB1855](#) [OA119AP-11-3WB1855](#)