


OAB13391 Series



AC Blower, ball bearing
133x91 (5.24"x 3.62")

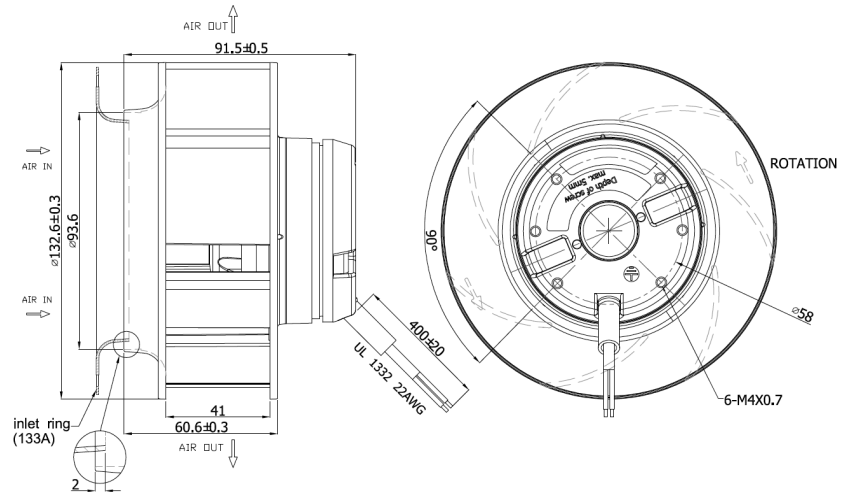

Backwards Curved Impeller

Frame & Impeller

Frame - Diecast aluminum
Impeller - UL94V-0 Thermoplastic

Connection

Lead Wires

Motor

AC, shaded pole, thermally protected

Bearing System

Dual Ball

Insulation Housing:

AC1500V / 1 minute

Insulation Resistance:

> 100 M ohms DC500V

Operating Temperature

-40 C ~ +60C


Life Expectancy

40,000 hours (L10, 40C)
Ball bearing

IP55 Rated

Weight 2.65 lbs.

m2

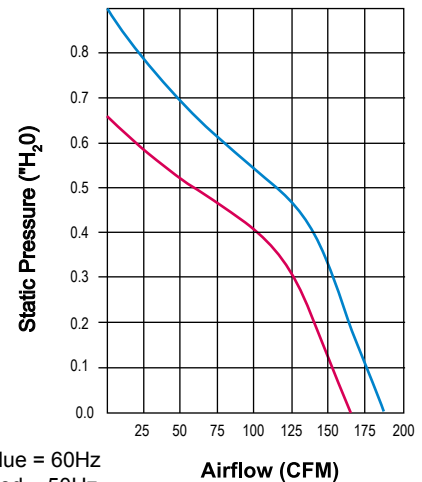

Blue = 60Hz
Red = 50Hz

Part Number	OAB13391-11-1WB	OAB13391-22-1WB
Nominal Voltage	115 VAC (50/60 Hz)	230 VAC (50/60 Hz)
Nominal Current (Amps)	0.50 / 0.43	0.24 / 0.21
Locked Current (Amps)	0.83 / 0.72	0.39 / 0.34
Rated Power	42 / 41 W	40 / 39 W
Rated Speed (RPM)	2780 / 3200	2780 / 3200
Airflow (CFM)	165 / 188	165 / 188
Noise Level (dB)	56 / 60	56 / 60
Max. Static Pressure	.65 / .88" H ₂ O	.65 / .88" H ₂ O

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OAB13391-11-1WB](#) [OAB13391-22-1WB](#)