

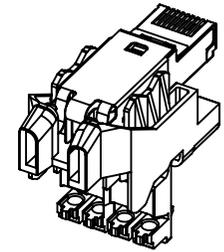
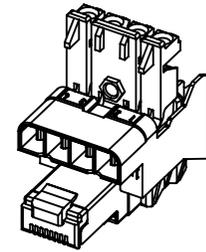
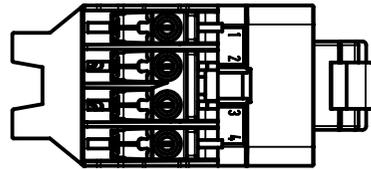


A

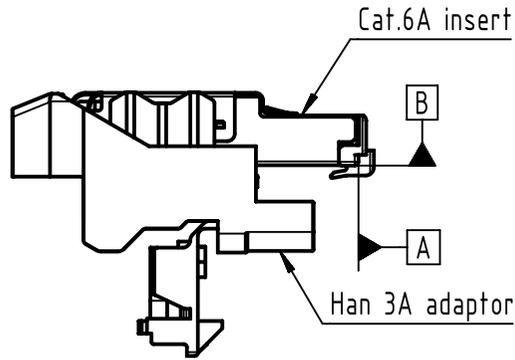


B

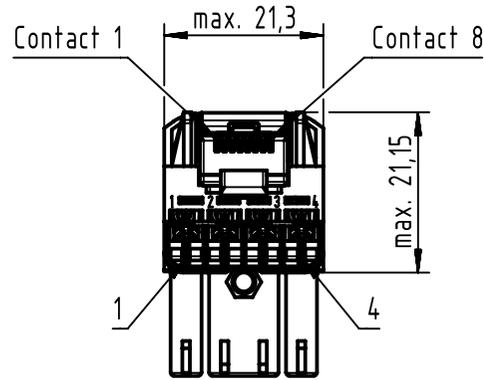

- For stranded conductors
AWG 28 up to AWG 24
- Max. wire diameter 1.05mm
- Cat.6A performance class EA
suitable for 1/10 Gigabit Ethernet
- Temperature range -40°C up to +70°C
- 750 mating cycles

C

Han 3A adaptor with closed lever

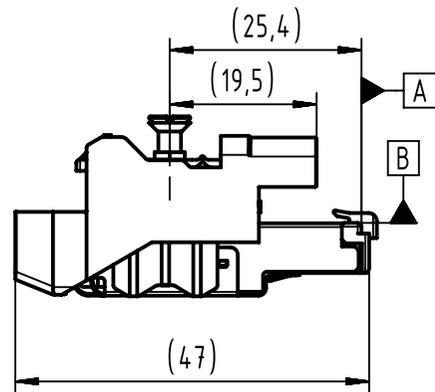

D

	All rights reserved Department EC PD - RO	All Dimensions in mm Original Size DIN A4			Scale 1:1	Free size tol.	Ref. Sub.
		Created by TAMAS	Inspected by POPESCUD	Standardisation HOFFMANN	Date 2017-09-05	State Final Release	
HARTING Electronics GmbH D-32339 Espelkamp		Title Han3A RJ45 Hybrid GL Cat6A insert 8+4p				Doc-Key / ECM-Nr. 100514368/UGD/002/D 500000118331	
		Type TB	Number 09451001720			Rev. D	Page 1/1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09451001720](#)