


Hyb.Cab.2XFO MM 50µm+3x2,5qmm;reel 500M"

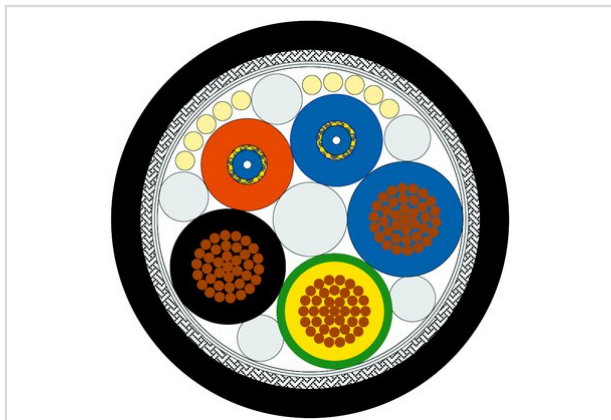

Part number	33 57 851 5000 002
Specification	Hyb.Cab.2XFO MM 50µm +3x2,5qmm;reel 500M"
HARTING eCatalogue	https://b2b.harting.com/33578515000002

Identification

Category	Cable
Specification	Not assembled
Type of cable	Hybrid cable (copper/FO)
Description of the cable	LC duplex Multimode

Version

Core structure	2x G50 / 125 µm 3x 2.5 mm²
----------------	-------------------------------

Technical characteristics

Cable length	500 m
Cable diameter	12.6 mm
Minimum bending radius	10x Cable diameter (repeated bending) 5x Cable diameter (singular bending)

Material properties

Material (cable)	PVC
------------------	-----

Commercial data

Packaging size	1
Net weight	110 kg
Country of origin	Germany
European customs tariff number	85447000

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[33578515000002](#)