

Technical Characteristics

Part Number

Han® 1A Kit

Hood	Top Entry
Housing	Locking Lever Coupler
Material	Polyamide Plastic
Protection Degree	IP20
Temp Rating	-30 to +90C
Cable Gland	Plastic
Cable Diameter	5.7 – 10mm
Insert	3+GND
Screw Terminals	18-14AWG
Wire Strip Length	7.5mm
Mating Cycles	>100
Flammability	V-0

Electrical Characteristics

Rated Current	10amps
Rated Voltage acc. UL	250V
Rated Impulse Voltage	6kV


73 10 100 0023



* Zip tie for discrete wires or cable included

Drawings and Assembly Information

Dimensions in mm

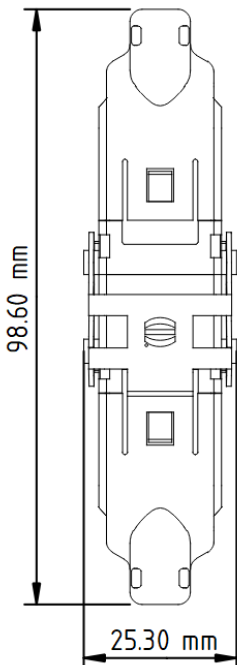

Tooling and Torque Values

Type	Tool	Torque (Nm)
Terminal Screws (M3)	Slotted 0.4 x 2.5	0.25

Kit Contents

Male Insert	09 10 003 2606
Female insert	09 10 003 2706
Hood & Gland (x2)	09 10 000 5300
Lever	09 10 000 5200

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[73101000023](#)