


D-SUBMINIATURE CONNECTORS:

K22XHT Series

High Temp. Right Angle PCB Mount 0.318" Footprint

K22XHT Series Dimensions

Dimensions in mm

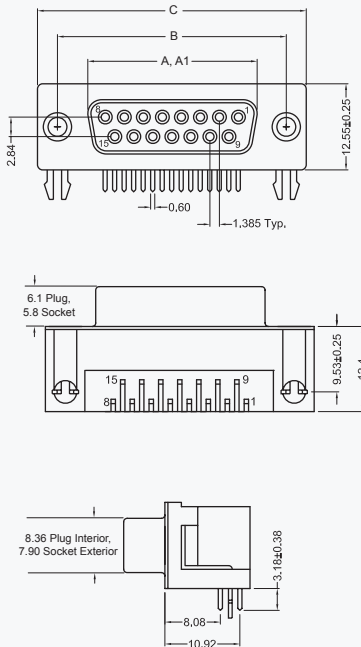

Shell Size In mm	A ±.010 ±0.25	A1 ±.010 ±0.25	B ±.005 ±0.13	C ±.015 ±0.38
9 (E)	.643 16.33	.666 16.92	.984 24.99	1.213 30.81
15 (A)	.971 24.66	.994 25.25	1.312 33.32	1.541 39.14
25 (B)	1.511 38.38	1.534 38.96	1.852 47.04	2.088 53.04
37 (C)	2.159 54.84	2.182 55.42	2.500 63.50	2.729 69.32

A = Exterior of Female Shell (S)
A1 = Interior of Male Shell (P)

2D Drawing	IGES	STEP	3D PDF
Solder Profile	CofC RoHS Compliant	CofC REACH Compliant	UL Plastic File
Certificate of Origin	Check Stock	Request a Sample	Send Us An Email

Generated Part Number

Part Number Builder

	-			
Series		Shell Size Contact	Contact Type	Mounting Option

Series

K22XHT - High Temperature Right Angle PCB Mount 0.318" Footprint

Shell Size-Contact Option

- E - 9 Contacts
- A - 15 Contacts
- B - 25 Contacts
- C - 37 Contacts

Contact Type

- P - Pin Contact (Plug)
- S - Socket Contact (Receptacle)

PC Board Mounting Option

- N - With Boardlocks and #4-40 UNC Threaded Inserts
- NJ - With Boardlocks and # 4-40 Jackscrews Installed

Contact Kycon for Other Options

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kycon:

[K22XHT-E9P-N30](#) [K22XHT-E9S-N](#) [K22XHT-C37S-NJ](#) [K22XHT-C37S-NJ30](#) [K22XHT-C37P-NJ30](#) [K22XHT-B25P-NJ30](#) [K22XHT-E9P-NJ30](#) [K22XHT-B25S-N](#) [K22XHT-A15P-N](#) [K22XHT-E9S-NJ](#) [K22XHT-C37S-N30](#) [K22XHT-C37S-N](#) [K22XHT-B25P-N](#) [K22XHT-A15P-N30](#) [K22XHT-B25S-N30](#) [K22XHT-C37P-N](#) [K22XHT-A15S-NJ30](#) [K22XHT-B25P-N30](#) [K22XHT-B25S-NJ30](#) [K22XHT-A15P-NJ](#) [K22XHT-A15S-N](#) [K22XHT-B25S-NJ](#) [K22XHT-C37P-NJ](#) [K22XHT-A15P-NJ30](#) [K22XHT-A15S-N30](#) [K22XHT-B25P-NJ](#) [K22XHT-E9S-N30](#) [K22XHT-C37P-N30](#) [K22XHT-E9S-NJ30](#) [K22XHT-E9P-N](#) [K22XHT-E9P-NJ](#) [K22XHT-A15S-NJ](#) [K22XHT-B25S-NJM30](#) [K22XHT-B25P-NJM30](#) [K22XHT-C37S-N15](#) [K22XHT-A15S-NVT15](#) [K22XHT-C37P-NVR](#) [K22XHT-B25S-NVR](#) [K22XHT-A15P-NVJ](#) [K22XHT-E9P-NR30](#) [K22XHT-E9P-NVJM15](#) [K22XHT-A15S-NT](#) [K22XHT-E9P-NT30](#) [K22XHT-B25P-NT15](#) [K22XHT-E9S-NR](#) [K22XHT-E9S-NVT15](#) [K22XHT-E9P-NV](#) [K22XHT-E9S-NT](#) [K22XHT-A15P-NJM30](#) [K22XHT-C37P-NR30](#) [K22XHT-A15S-NJM30](#) [K22XHT-A15P-NV](#) [K22XHT-B25P-NVT15](#) [K22XHT-E9S-NVJM15](#) [K22XHT-A15P-NVT15](#) [K22XHT-B25P-N15](#) [K22XHT-A15P-NVJM](#) [K22XHT-A15S-NT30](#) [K22XHT-C37S-NJM15](#) [K22XHT-E9S-NJM30](#) [K22XHT-A15S-NVJ15](#) [K22XHT-E9S-NT15](#) [K22XHT-A15P-NVJ15](#) [K22XHT-B25S-NVJM15](#) [K22XHT-A15S-NJ15](#) [K22XHT-E9P-NVT30](#) [K22XHT-E9S-NVT30](#) [K22XHT-E9S-NVJ](#) [K22XHT-C37S-NVT](#) [K22XHT-B25P-NVJM](#) [K22XHT-A15S-NVJM15](#) [K22XHT-A15P-NT15](#) [K22XHT-C37P-NV](#) [K22XHT-E9P-NT](#) [K22XHT-B25P-NVJM15](#) [K22XHT-C37P-NVT15](#) [K22XHT-C37S-NVT15](#) [K22XHT-C37P-NJ15](#) [K22XHT-B25P-NR15](#) [K22XHT-C37S-NV](#) [K22XHT-B25S-N15](#) [K22XHT-E9P-NJM](#) [K22XHT-C37S-NJM30](#) [K22XHT-B25S-NVJ](#) [K22XHT-B25P-NVR15](#) [K22XHT-E9P-NVJ15](#) [K22XHT-C37P-NVR30](#) [K22XHT-E9P-NJM15](#) [K22XHT-B25P-NT](#) [K22XHT-B25P-NVR30](#) [K22XHT-E9S-NJM15](#) [K22XHT-C37P-NV15](#) [K22XHT-C37S-NVT30](#) [K22XHT-A15S-NV15](#) [K22XHT-A15P-NR15](#) [K22XHT-C37S-NV15](#) [K22XHT-E9P-NJ15](#) [K22XHT-E9P-NVT](#) [K22XHT-B25P-NVJM30](#) [K22XHT-A15P-NVR30](#)