

Specification Sheet

USB2.0 Flash Drive Handy Steno AH332



Apacer
Access the best

Apacer Technology Inc.

4th Fl., 75 Xintai 5th Rd., Sec.1, Hsichih, Taipei Hsien 221, Taiwan

Tel: +886-2-2698-2888 Fax: +886-2-2698-2889

www.apacer.com

Table of Contents

<u>1. Product Introduction</u>	3
<u>2. Product Features</u>	3
<u>3. Specification</u>	4
<u>4. Certifications</u>	4

1. Product Introduction

The AH332 USB flash drive features a creative design — the arrow-shaped push key that allows you to operate the USB single-handedly. Available in four lively and dazzling colors — forest green, sky blue, bright yellow and glamorous purple, along with its black coated casing, the USB flash drive demonstrates sharp contrasts with bright colors, resembling a speedy arrow in the dark!

The USB flash drive not only looks sleek with its main design, the “brightly-colored arrow-shaped key”, but also looks like a flying arrow with its obsidian black finish, sporting the thrill and tension of speed. This design perfectly matches the image of the younger generation — the vitality as well as the power of action. The matte- finished push key creates a contrast with the glossy black surface, which makes the USB the center of attention. The USB flash drive allows users to operate single-handedly and easily. There is no need to worry about losing a cap; it is both practical and aesthetic.

Only 5.5 centimeters in length, 2.1 centimeters in width and 0.98 centimeters in thickness, the AH332 is exquisite, lightweight and sleek. It is available in four colors and capacities — respectively, 2GB Forest Green, 4GB Sky Blue, 8GB Bright Yellow and 16GB Glamorous Purple, perfectly addressing your needs for quick storage in your digital life. The environmentally friendly AH332 series also meets the RoHS criteria and provides a lifetime warranty. In terms of compatibility, it is fully compatible with Windows 7 and is able to run great with the latest computer. In addition, the Apacer USB flash drive comes with free ACE compression software that provides data compression, decompression and password protection, which easily increases the storage capacity by 500%, while ensuring data security and privacy.


2. Features

- USB 2.0 Hi-Speed interface
- Easy plug & play
- Retractable USB connector- Capless design
- Strap hole: Allow easy carry
- RoHS compliant

3. Specifications

Specifications	
Interface	High-speed USB 2.0 certified, backwards compatible with USB 1.1
Power supply	USB bus powered No external power required
Power consumption	115mA (max.)
Operating Systems Supported	Windows ME/XP/2000/Vista/7, Mac OS 8.6 and Linux 2.4.0 or above
Capacity	2GB~ 16GB
Operating Temperature	0° C to +60° C (32° F to 140° F)
Storage Temperature	-20° C to +60° C (-4° F to +140° F)
Dimensions	(L) 55 x (W) 21 x (H) 9.8 mm
Weight	9g

4. Certifications

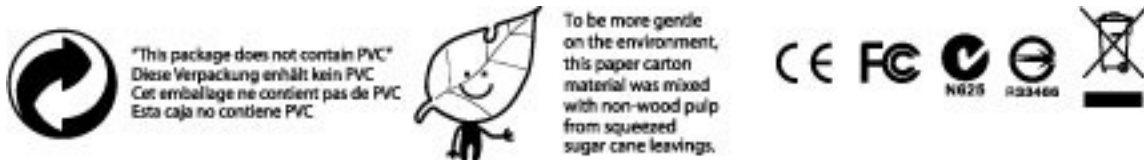

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Apacer:](#)

[AP2GAH332B-1](#) [AP4GAH332B-1](#) [AP8GAH332B-1](#) [AP16GAH332B-1](#) [AP16GAH332B](#) [AP4GAH332B](#)
[AP2GAH332B](#) [AP8GAH332B](#)