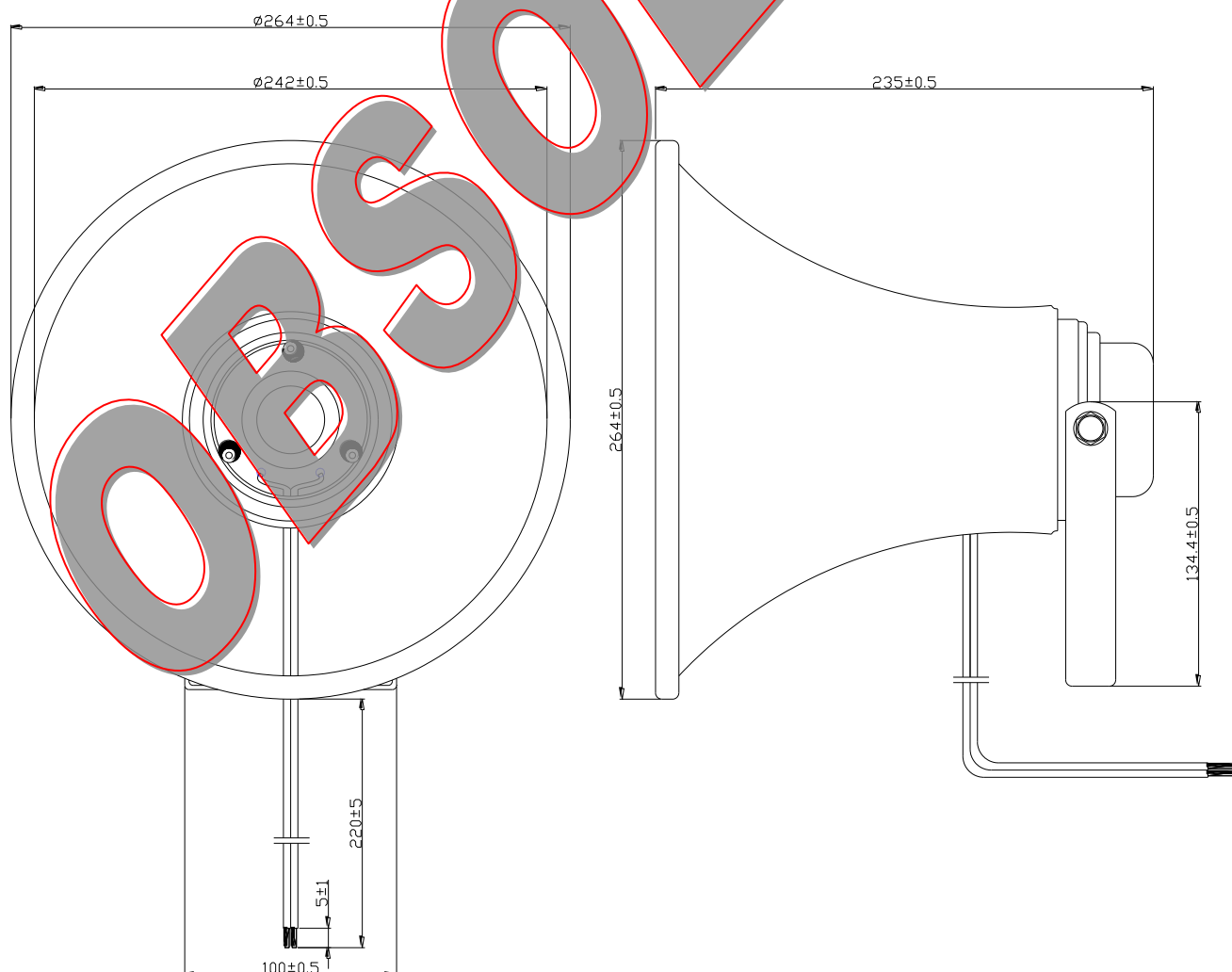


Specifications:

Resonant Frequency (Hz)	500 ~ 7000
Impedance (Ω)	8 ± 2
Input Power (Watts RMS)	25
SPL (dB @ 1.0W / 1.0 m)	98.7
Operating Temperature ($^{\circ}\text{C}$)	$-20 \sim +70$
Storage Temperature ($^{\circ}\text{C}$)	$-30 \sim +80$
Housing	Aluminum (Color: Gray)
Leading Wire	20 AWG
Weight (Grams)	962.8
Locations	For indoor/outdoor use (No Salt environment)
Options	For other options contact factory

Dimensions: (units: mm)
ROHS Compliant


Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PH-260Q](#)