


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0082226010
Status: Active
Description: 2.54mm Pitch Round Conductor Flat Cable - 22 AWG (7 x 30) Stranded, Topcoat, 10 Circuits, Reel 30.48m Length

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable
Series	8867
Crimp Quality Equipment	Yes
Geographic Area	Asia
Product Name	Ribbon
UPC	800754954204
Physical	
Cable Length	30.48m
Circuits (Loaded)	10
Insulation	PVC
Net Weight	1975.620/g
Packaging Type	Reel
Pitch - Termination Interface	2.54mm
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	22
Wire/Cable Type	(7x30) Stranded, Topcoat
Electrical	
Current - Maximum per Contact	N/A
Voltage - Maximum	300V
Material Info	
Engineering Number	8867-10-100B
Reference - Drawing Numbers	
Sales Drawing	SD-8867-001

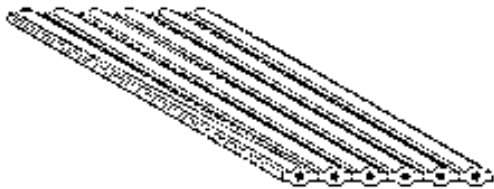

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - ED/30/2017 (7 July 2017) Halogen-Free Status Not Low-Halogen Need more information on product environmental compliance? Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[8867](#) Series

Use With
[70400](#) C-Grid SL IDT Connector Assembly.
[70475](#) SL IDT Connector Assembly. [7720](#)
KK IDT Double Cantilever Contact

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[82-22-6010](#)