

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395040517

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

3.50mm Pitch Eurostyle Horizontal Plug, with Retention Screws, Gold (Au) Plated, 17 Circuits

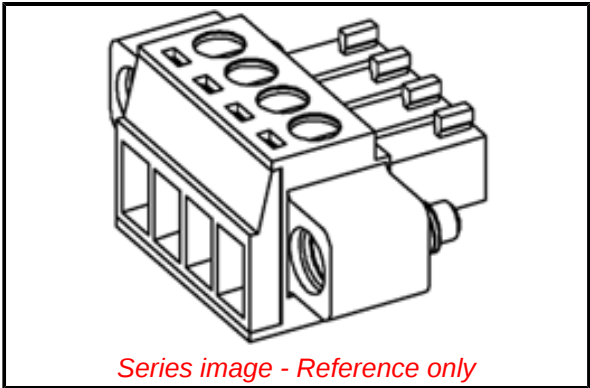

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification PS-39500-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification		
UL		E48521
General		
Product Family		Terminal Blocks
Series		39504
Application		N/A
Component Type		Plug
Overview		Eurostyle Terminal Blocks
Product Name		ESE, Eurostyle Pluggable
Type		Euro Block
UPC		822350441759
Physical		
Circuits (Loaded)		17
Entry Angle		Vertical
Lock to Mating Part		Yes
Number of Rows		1
Orientation		Horizontal
Panel Mount		No
Pitch - Mating Interface		3.50mm
Pitch - Termination Interface		3.50mm
Polarized to Mating Part		Yes
Stackable		No
Temperature Range - Operating		-40° to +105°C
Wire Size AWG		16, 18, 20, 22, 24, 26, 28, 30
Wire Size mm²		0.05-1.31
Electrical		
Current - Maximum per Contact		8.0A
Voltage - Maximum		300V
Material Info		
Reference - Drawing Numbers		
Product Specification		PS-39500-001-001
Sales Drawing		SD-39504-001

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

China RoHS

Search Parts in this Series

39504 Series

Mates With

Most 3.50mm Pitch Industry Standard PCB Headers, 39505 Vertical PCB Header with Threaded Retention Inserts, 39506 Horizontal PCB Header with Threaded Retention Inserts

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39504-0517](#)