

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.



Material	High Conductivity Seamless Copper Tube
Plating	Electro-Tin
Wire Size	4 AWG, 3 AWG & 2 SOL
Wire Type	Stranded Copper; Class B: Compact, Compressed or Concentric, Class C: Concentric
Wire Strip Length	1-1/8 in.
Stud Size	1/2 in.
UL Listed Wire Connector	Yes, for applications up to 35kv. Consult cable manufacturer for voltage stress relief instructions with applications greater than 2000 volts.
UL Temperature Rating	90° C
C.S.A Certified Wire Connector	Yes
Panduit Color Code on Barrel	GRAY
Panduit Die Index No. on Barrel	P29
Alternate Industry Die Index No. () on Barrel	(8)



CERTIFIED



LISTED
Wire Connector

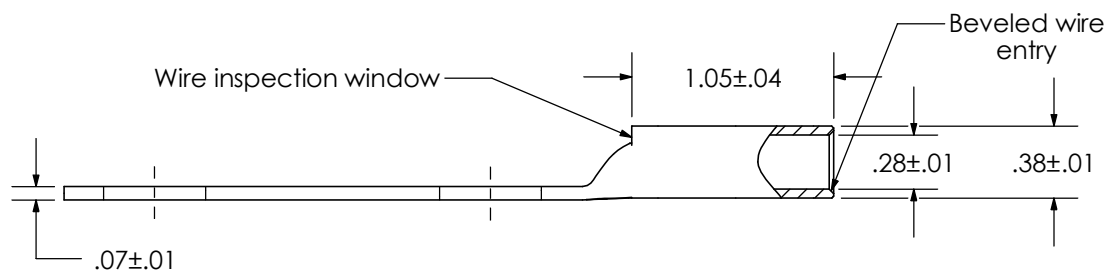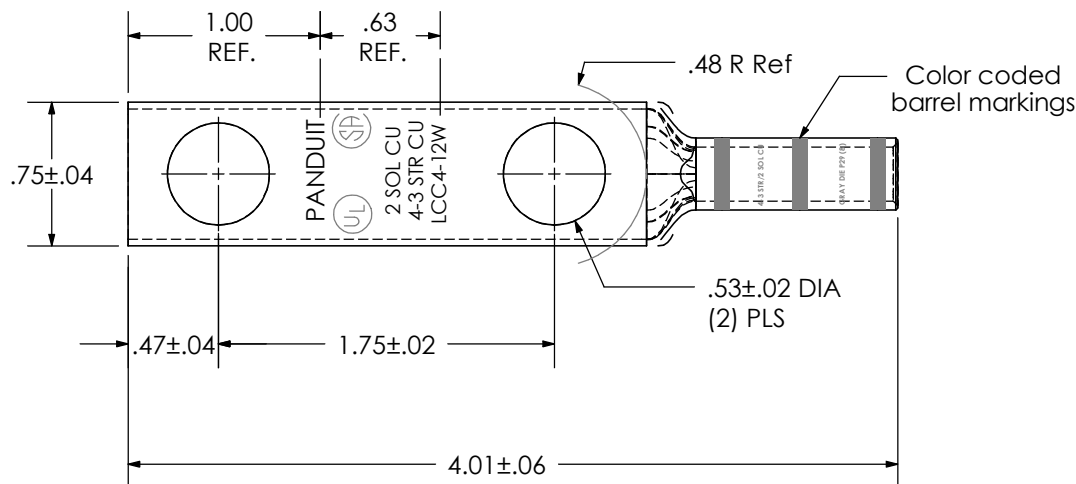

02	10/09	JESH	JESH	DIMENSIONS 4.01" +/--.06" WAS 3.98" +/--.06", .47" +/--.04" WAS .50" +/--.04"
01	12/07	JESH	JESH	MOVED TEXT LOCATION TO CENTER OF PART
				ADDED DIMENSION 1.00" REF., .63" REF.
00	6/07	JHNU	LEM	RELEASED

REV	DATE	BY	CHK	DESCRIPTION	ECN	SCALE	DRAWING NO / CAD FILE
						N/A	LCC4-12W-CUST

PANDUIT

CORP. TINLEY PARK, ILLINOIS

LCC4-12W-L
Copper Lug - Two-Hole, Long Barrel with Window

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Panduit:

LCC4-12W-L