

Wiha Insulated Pliers and Cutters Sets


 1000volt

- Pliers drop-forged from special tool steel, individually high frequency induction hardened, chrome and nickel plated, mirror-polished.

- In zipper carry case

32891 10 Piece Pliers & Screwdriver Set. Insulation According to VDE 0682/part 201, EN/IEC 60900, ASTM F-1505-01, NFPA70E and CSA,  up to 1000 volt. Individually Tested.



Item# 32891 Set Includes:	 lbs. 5.44
32818 - 8.0" Combination Pliers	32808 - 8.0" Long Nose
32838 - 8.0" Side Cutters	32848 - 6.75" Cable Cutters
32860 - 6.3" Universal Wire Stripper	
Insulated Phillips #1, #2, #3	Insulated Slotted 4.5, 6.5mm


 1000volt

- Pliers drop-forged from special tool steel, individually high frequency induction hardened, chrome and nickel plated, mirror-polished.

32889 8 Piece Pliers & Cutters Set. Insulation According to VDE 0682/part 201, EN/IEC 60900, ASTM F-1505-01, NFPA70E and CSA,  up to 1000 volt. Individually Tested.



Item# 32889 Set Includes:	 lbs. 4.53
32806 - 6.3" Long Nose Pliers	32808 - 8.0" Long Nose Pliers
32814 - 6.3" Lineman's Pliers	32832 - 6.3" Diagonal Cutters
32820 - 9.0" Lineman's Pliers	32838 - 8.0" High Lev. Cutters
32860 - 6.3" Wire Stripping Pliers	15000 - Electrician's Knife

Wiha Inomic 1000Volt Insulated Pliers

Insulation Standards:

EN/IEC 60900, ASTM F-1505-01, NFPA70E & CSA

Tools Meet 10,000 Volt Test Standards Rated to 1000 Volt ac or 1500 Volt dc


 1000volt

32850 Inomic Combo Pliers. Insulation According to EN/IEC 60900, ASTM F-1505-01, NFPA70E & CSA,  up to 1000 volt. Individually Tested. DIN ISO 5749 Precision machined forged head. Induction hardened for longest tool life. Cross hatched flat jaw & deep cut radius jaws for secure gripping of the work piece. Cutting edges are matched for precise cutting action. Award winning ergonomic design with head mounted at 23° angle to grip for reduced user fatigue. Palm side of grip has molded soft panel for added comfort in prolonged use.


Item No.	mm	Inch	Cutting Capacity Copper AWG	Pkg.	lbs.
32850	180	7.0	#6	1	.46

32852 Inomic Long Nose Pliers

Item No.	mm	Inch	Cutting Capacity Copper AWG	Pkg.	lbs.
32852	160	6.3	#6	1	.43

32854 Inomic Diagonal Cutters

Item No.	mm	Inch	Cutting Capacity Copper AWG	Pkg.	lbs.
32854	160	6.3	#6	1	.41

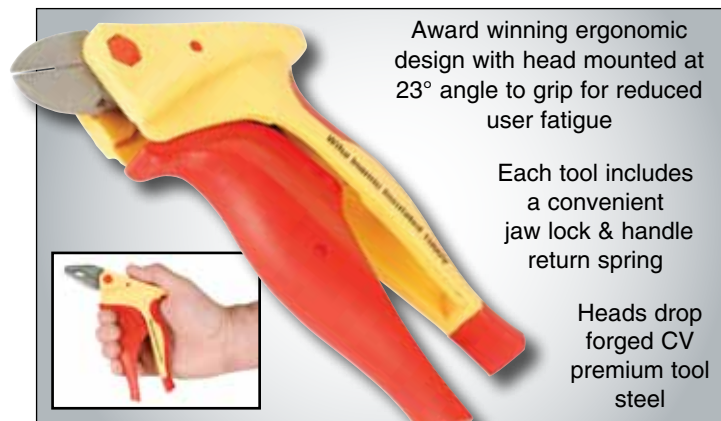

Award winning ergonomic design with head mounted at 23° angle to grip for reduced user fatigue

Each tool includes a convenient jaw lock & handle return spring

Heads drop forged CV premium tool steel

Tools Meet 10,000 Volt Test Standards Rated to 1000 Volt ac or 1500 Volt dc

 1000V

32859 3 Pc. Insulated Inomic Pliers/Cutters Set Meets ASTM, EN/IEC, NFPA, CSA, ISO specifications. Award winning ergonomic design with head mounted at 23° angle to grip for reduced user fatigue.

Item# 32859 Set Includes:	 lbs. 1.45
32850 - Combo Pliers	32854 - Diagonal Cutters
32852 - Long Nose Pliers	91230 - Inomic Holster (Includes 3)




Three Holsters Included



91230 Inomic Canvas Holster

Item No.	Width Size	Height Size	 lbs.	 pkg.
91230	4.0 x	4.5	.05	1

Holds any Inomic Pliers



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Wiha:

[91230](#) [32850](#) [32852](#) [32854](#) [32889](#) [32859](#) [32891](#)