
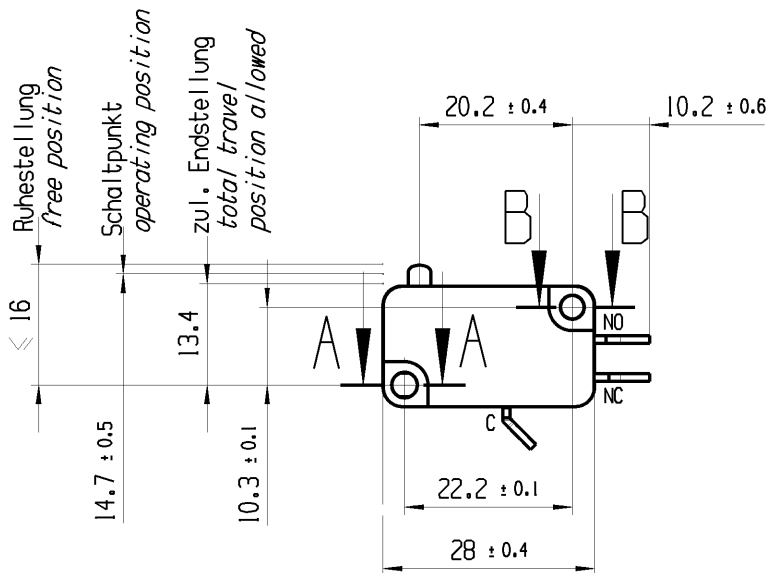
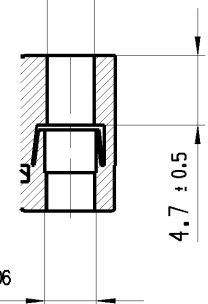


A-A
2:1

B-B
2:1

3.35 ± 0.05 x 3.08 ± 0.06

Ø 3.08 ± 0.06

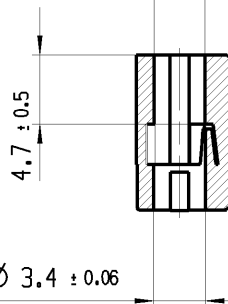

Aufschrift
Marking



 
1005 µ T100
20141/400~10E3
16141/400~50E3
10161/250~50E3

16A 125V AC 1/2HP
16A 250V AC 1/2HP

R109

Hersteldatum:
Werk / Herstelljahr / -woche
nach DIN EN 60062

data code of manufacture:
site / year / week acc. to DIN EN 60062



Wechsler 1-polig
single pole changeover

Schalt-Betaetigungskraft 2.4 bis 3.8 N
actuating force 2.4 up to 3.8 N

Differenzweg 0.3 mm
movement differential

fuer Form und Lage FOR SHAPE AND LOC.	⊙ ≡	0.1	Allgemeintoleranzen UNTOLERANCED DIMENSIONS					Pause COPY	Blatt SHEET 01	TYP K	Zeichn./DRAWING NO. 10050404	Index d			
			PROJEKTION	Abmasse und Nennmassbereiche Angaben in mm	Laenge LENGTH Radien RADII	0-6 ± 0.1 ± 0.2	Laenge LENGTH						Radien RADII		
fuer Winkel FOR ANGLE ± 2	± 0.25 10 ± 0.1 1-0.25	⊕ ⊙	ALL DIMENSIONS ARE IN MILLIMETRES	>6-15 ± 0.15 ± 0.3 >15-30 ± 0.2 ± 0.5 >30-70 ± 0.3 >70-120 ± 0.4 >120 ± 0.8	± 10%	0 10 20 30mm	SCHNAPPSCHALTER								
c	28825	08.12.99	PFU					CAD: NX V6.0					snap action switch		
b	20923	27.06.91	WA					gez./DRAWN BY 20.09.12 ZES					Ⓜ MARQUARDT		
a	19596	15.09.89	WA					gepr./CHECKED BY							
	18869	22.09.88	WA	d	80501	04.03.13	ZES	Ersatz fuer/REPLACEMENT OF Zg.gl.Nr.v.08.12.1999							
Ausg. ISSUE	Aenderung REVISION	gez. DRAWN BY		Ausg. ISSUE	Aenderung REVISION	gez. DRAWN BY									

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Marquardt:](#)

[1005.0404](#)