



ø200 mm type

Model no.	Surface treatment	Mass (g)	Applicable model no.
109-1102	Nickel-chrome plating (silver)	100	9GV2048P0G201

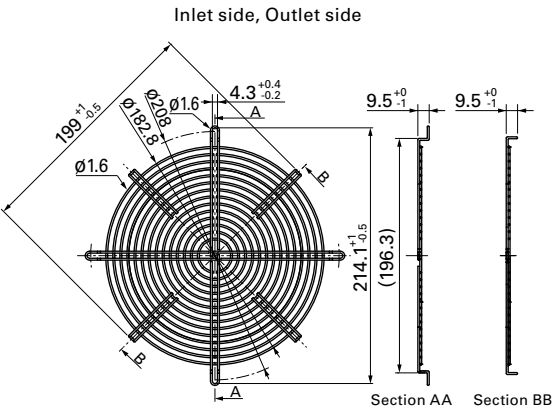


Model no.	Surface treatment	Mass (g)	Applicable model no.
109-1103	Nickel-chrome plating (silver)	80	9GV2048P0G201

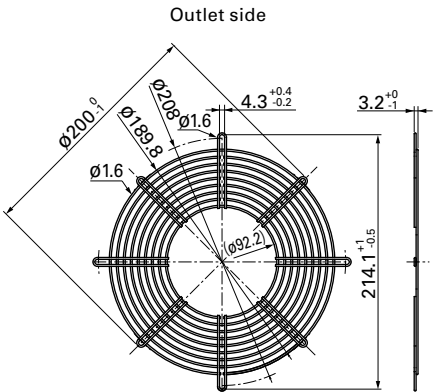


ø200 mm type

Model no.	Surface treatment	Mass (g)	Applicable model no.
109-720	Nickel-chrome plating (silver)	84	109E2024□□□□
109-720H	Cation electropainting (black)		9EC20□□□001

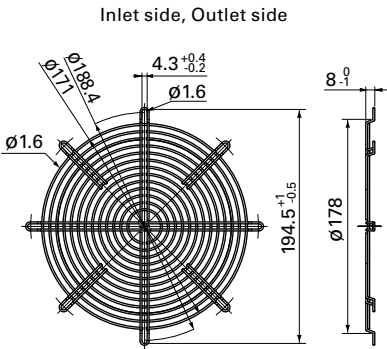


Model no.	Surface treatment	Mass (g)	Applicable model no.
109-721	Nickel-chrome plating (silver)	66	109E2024□□□□
109-721H	Cation electropainting (black)		9EC20□□□001

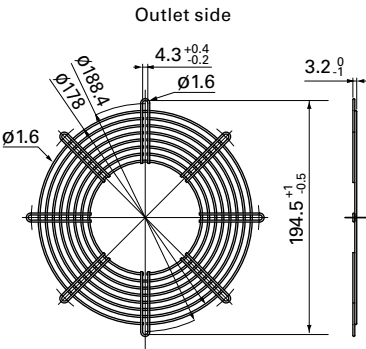

Mounting example

Axial fan

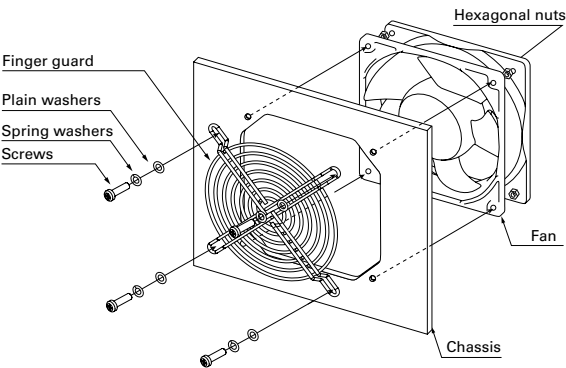

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Sanyo Denki:

[109-720](#) [109-721](#) [109-1102](#) [109-721H](#) [109-720H](#) [109-1103](#)