


COMBINATION TOOL HDC 43

R282.868.201

SERIES

OUT

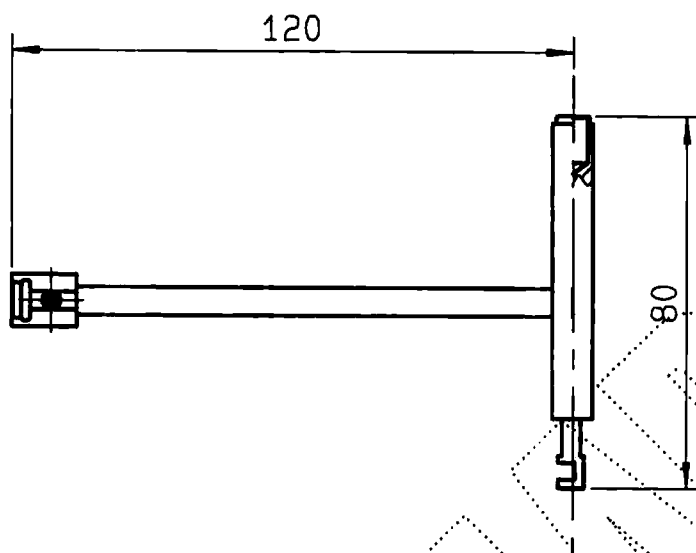

NOMINAL IMPEDANCE	Ω	CABLES	
FREQUENCY RANGE	GHz		
TEMPERATURE RATING	$^{\circ}\text{C}$		
V.S.W.R	+ x F (GHz) Maxi		
RF INSERTION LOSS	$\sqrt{F}$ (GHz) dB Maxi		
VOLTAGE RATING	Veff Maxi		
DIELECTRIC WITHSTANDING VOLTAGE	Veff Mini	OTHERS CHARACTERISTICS	
INSULATION RESISTANCE	M Ω Mini		
HERMETIC SEAL	Atm.cm ³ /s	CABLE RETENTION	N Mini
LEAKAGE (pressurized only)		CENTER CONTACT RETENTION	
MECHANICAL DURABILITY	Cycles	Axial force - mating end	N Mini
WEIGHT	gr	Axial force - opposite end	N Mini
SPECIFICATION		Torque	cm.N Mini
		RECOMMENDED TORQUES	
		Mating	cm.N
		Panel nut	cm.N
		Clamp nut	cm.N

CONNECTOR PARTS	MATERIALS	FINISH	(all values are given) (in micrometers)
BODY			
OUTER CONTACT			
CENTER CONTACT			
INSULATOR	-		
GASKET	-		
OTHERS PIECES			

ISSUE

CREATION DATE

FILE PART-NUMBER

9904A00

13-MAR-97

97-0106-055



RADIALL®

The information given here is subject to change without notice.
Design changes may be in order to improve the product.

Connect to the future

KAM DE A

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Radial:

R282868201