



MUSBS-05-S-B-TH-TR



SPM-05-S-B-VT1-PF

SPM-05-S-B-RA-PF



SPM, MUSBS SERIES

IP68 SEALED MINI USB PORT

Mates with:
USBC

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com?SPM

Insulator Material:

Black Liquid Crystal Polymer

Contact Material:

Phosphor Bronze

Shield Material:

Phosphor Bronze

Plating:

30μ" (0,76μm) Au over

50μ" (1,27μm) Ni, Sn on tail

Operating Temp Range:

-55°C to +125°C

Current Rating:

1.9A per contact

Voltage Rating:

190 VAC

Contact Resistance:

15 mΩ max charge from initial

Minimum Cycles:

1000

Seal: Silicone

RoHS Compliant: Yes

Lead-Free Solderable: Yes

ALSO AVAILABLE

- Sealed port USB and RJ45 in development. Call Samtec.
- See our AccliMate™ IP68 sealed connectors for a full line of rugged Panel & I/O interfaces.

SPM

NO. OF
POSITIONS

PLATING

B

TERMINATION

PF

-05

-S

= 30μ" (0,76μm)
Gold on Mating Area,
Tin on Tails

-RA

= Right Angle

(Maximum panel thickness (2,03mm) .080")

-VT1

= Vertical Through-hole

(Maximum panel thickness (2,03mm) .080")






-VT2

= Vertical Through-hole

(Maximum panel thickness (5,21mm) .205")

ALSO AVAILABLE

Dust Cap: DCA-SPM-01

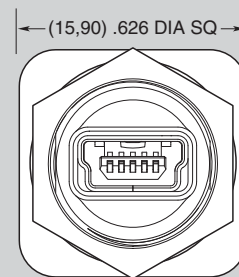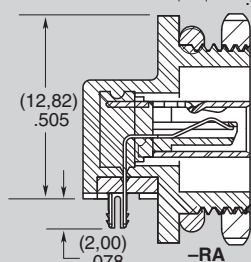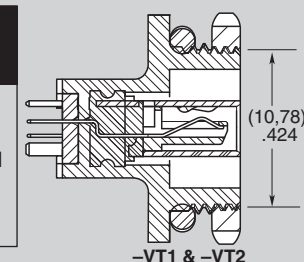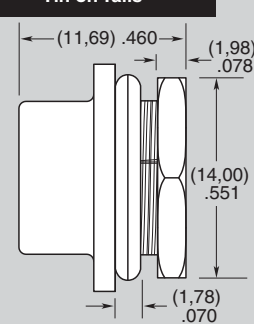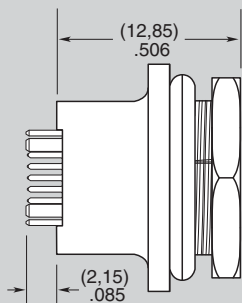

-VT1 & -VT2

-RA

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com?MUSBS

Insulator Material:

Black High Temperature

Contact Material:

Phosphor Bronze

Shell Material:

Phosphor Bronze

Plating:

Gold on Mating Area,

Nickel on Shell, Tin on Tails

Operating Temp Range:

-50°C to +85°C

Current Rating:

2A per contact

Voltage Rating:

30 VRMS

Contact Resistance:

50 mΩ max

Minimum Cycles:

5000

RoHS Compliant:

Yes

Lead-Free Solderable:

Yes

MUSBS

NO. OF
CONTACTS

PLATING

TYPE

TH

TR

MUSBS
= Sealed Mini USB

-05

-S




= 30μ" (0,76μm)
Gold on
Mating Area,
Tin on Tails

-B

= B Type

-TR

= Tape
& Reel
Packaging

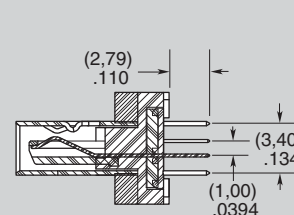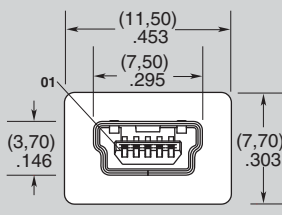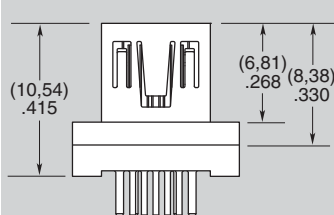

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC NORTHERN CALIFORNIA • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-6083 3766
SAMTEC TAIWAN • Tel: 886-2-2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[SPM-05-S-B-VT1-PF](#) [SPM-05-S-B-VT2-PF](#) [SPM-05-S-B-RA-PF](#)