

PART NAME	NON-METALLIC ENCLOSURE (STYLE A)	PART No.	NBA-10144 & NBA-10164
-----------	----------------------------------	----------	-----------------------

MATERIAL:

SOLID BODY & COVER

ABS/PC BLENDED PLASTIC

UL94-5VB FLAMMABILITY RATING

CLEAR COVER

POLYCARBONATE PLASTIC

UL94V-0 FLAMMABILITY RATING

UV STABILIZED

LATCHES, HINGES & WALL MOUNTING BRACKETS

STAINLESS STEEL





FINISH:

BODY

LIGHT GRAY

COVER

LIGHT GRAY OR CLEAR

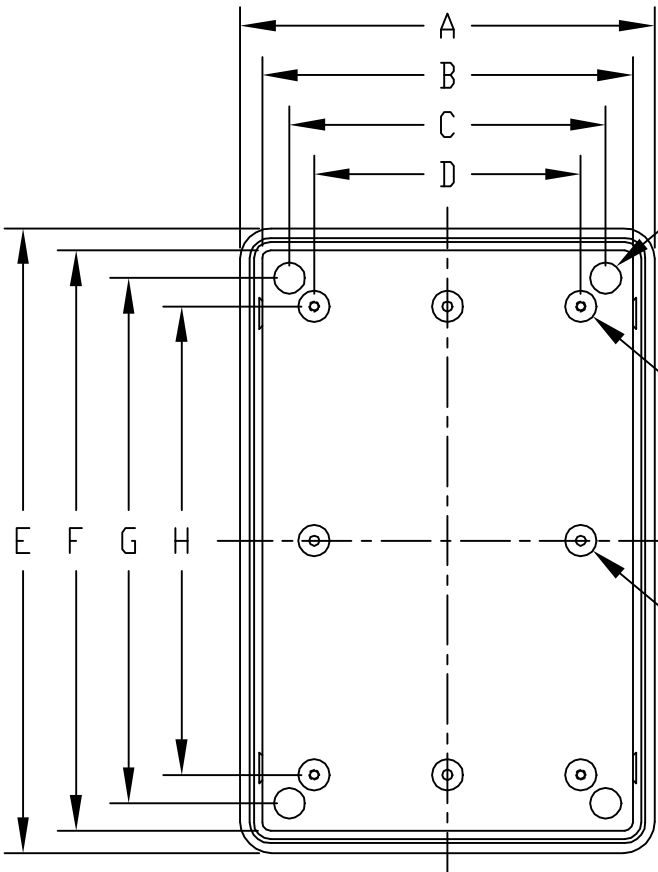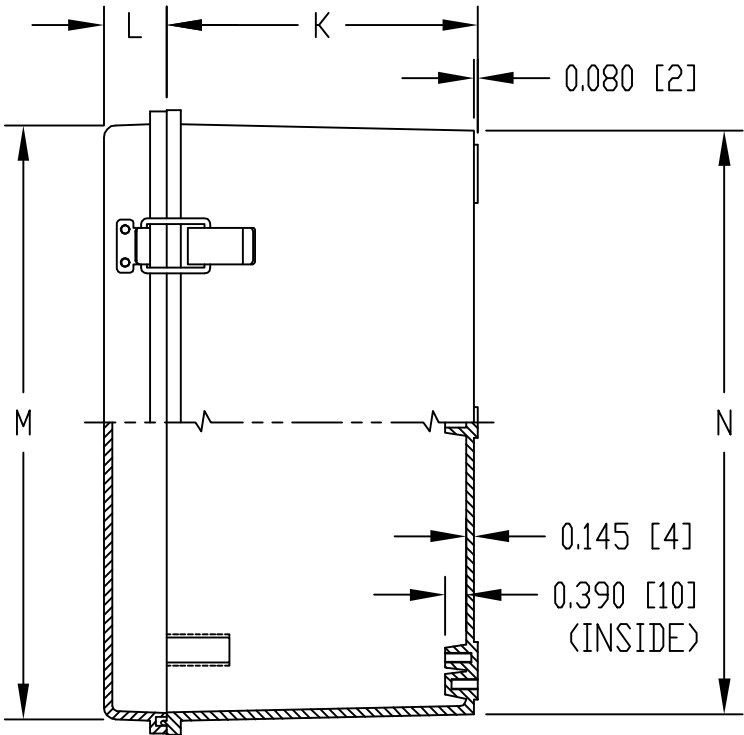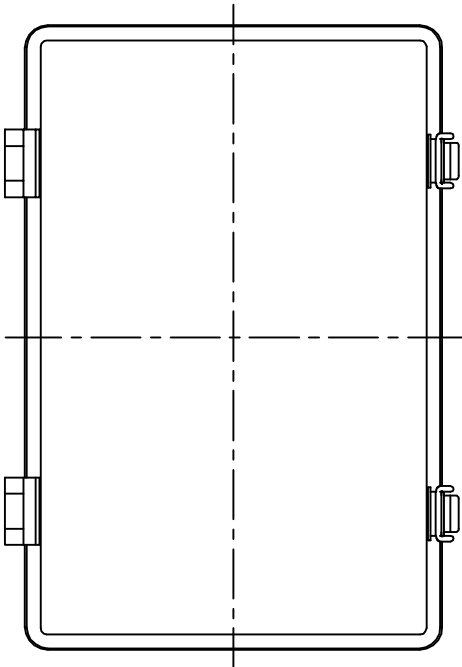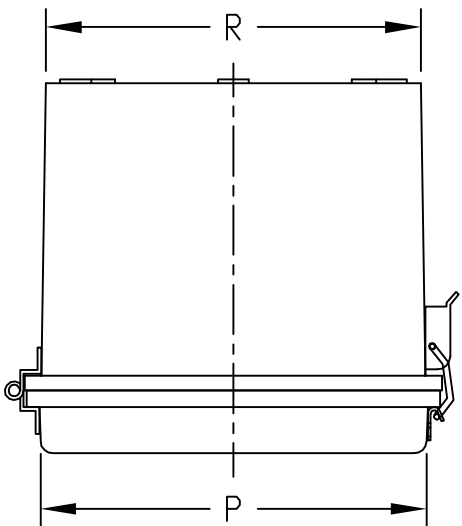

VIEW LESS COVER

0.590 [15] DIA. BOSS WITH M5 x 0.8mm THREADED BRASS INSERT

(4) PLACES (FAR SIDE)

0.590 [15] DIA. BOSS WITH M5 x 0.8mm THREADED BRASS INSERT

(4) PLACES

0.590 [15] DIA. BOSS WITH 0.197 [5] DIA. HOLE x 0.395 [10] DEEP

(4) PLACES

BOSSSES ACCEPT M6 METRIC OR 0.250" STD. SHEET METAL SCREWS x 0.375 [9] LG. (NOT SUPPLIED)

COVER INCLUDES GRAY POLY-URETHANE GASKET.

NOTE:

UNIT COMES COMPLETE WITH (4) WALL MOUNTING BRKTS. & (4) M5 x 10mm LG. TRUSS HD. MACHINE SCREWS (NOT SHOWN)

INTERNAL HINGED PANEL MOUNTING BRACKETS, AIR & MOISTURE VENTS, STAINLESS STEEL LOCKING HASP AND GALVANIZED STEEL INTERNAL PANEL ARE NOT INCLUDED, BUT CAN BE PURCHASED SEPARATELY.

INDUSTRY STANDARDS:

UL508 TYPE 1, 2, 4, 4X INDOOR, 12 & 13

NEMA TYPE 1, 2, 4, 4X, 12 & 13

IEC529-IP65

DIMENSIONS =

INCHES

[MILLIMETERS]

NOTE:

ALL DIMENSIONS HAVE ±0.039 [±1] TOLERANCE UNLESS OTHERWISE SPECIFIED

PART NO.		DIMENSIONS													
SOLID COVER	CLEAR COVER	A	B	C	D	E	F	G	H	K	L	M	N	P	R
NBA-10144	NBA-10164	7.848 [199]	7.021 [178]	5.990 [152]	5.050 [128]	11.832 [301]	10.989 [279]	9.949 [253]	8.872 [225]	5.899 [150]	1.186 [30]	11.253 [286]	11.060 [281]	7.308 [186]	7.100 [180]

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Bud Industries:](#)

[NBA-10164](#) [NBA-10144](#)