
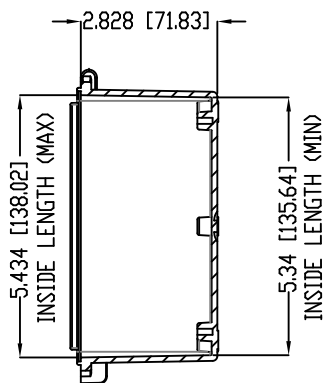


MATERIAL	FLAMMABILITY RATING	CONTINUOUS OPERATING TEMP.
ABS	UL94-HB	-40°C ~ +60 °C / -40°F ~ 140°F
CLEAR PC	UL94-V0 UV STABILIZED	-40°C ~ +130 °C / -40°F ~ 266°F
ABS / PC BLEND	UL94-5VA	-40°C ~ +85 °C / -40°F ~ 185°F
PBT / PC BLEND	UL94-5VA + UV (f1)	-40°C ~ +75 °C / -40°F ~ 167°F


FINISH:  
BODY\_\_\_\_\_ LIGHT GRAY  
COVER\_\_\_\_\_ LIGHT GRAY OR CLEAR  
LATCHES & HINGES\_\_\_\_\_ PLASTIC  
WALL MOUNTING BRACKETS\_\_ STAINLESS STEEL  
& HARDWARE

DRAWING FOR REFERENCE  
WE RESERVE THE RIGHT TO MAKE CHANGES TO OUR  
STANDARD PRODUCTS. PLEASE CONSULT WITH BUD INDUSTRIES  
PRIOR TO USING THIS DRAWING FOR DESIGN PURPOSES.



BODY

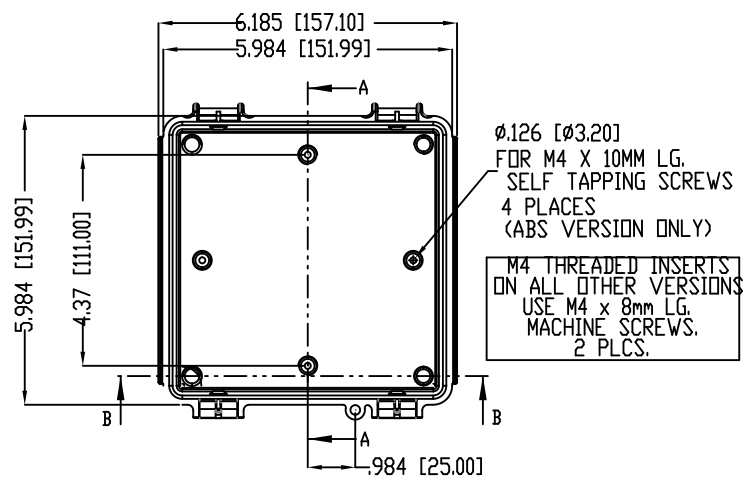

SECTION A-A

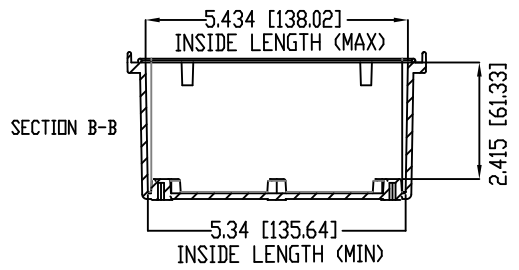


SECTION B-B

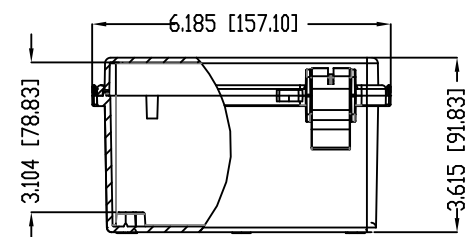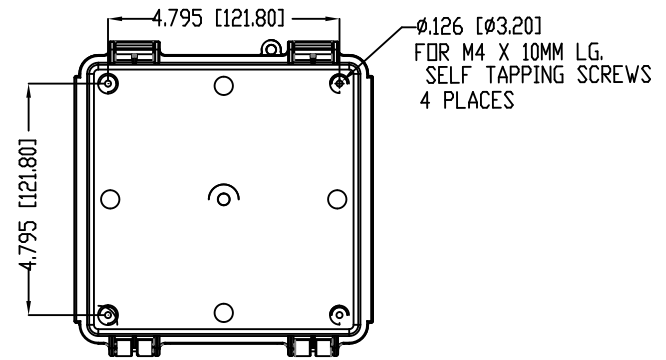

ASSEMBLY

COVER

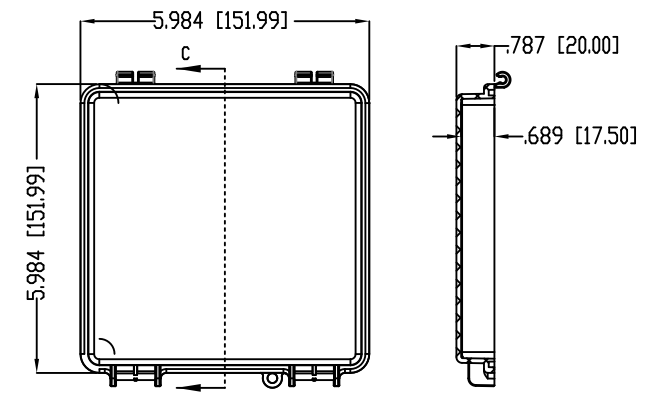

SECTION C-C

NOTES:

- 1) UNIT COMES COMPLETE WITH: (4) WALL MOUNTING BRACKETS & (4) M4 x 10mm LG. SELF-TAPPING SCREWS. (NOT SHOWN)
- 2) BOXES DESIGNED TO MEET FOLLOWING STANDARDS: NEMA 1,2,4,4X, AND IEC529-IP65 REQUIREMENTS.

TOLERANCES:

ALL DIMENSIONS HAVE  
 $\pm 0.039$ in [ $\pm 1$ mm] TOLERANCE  
UNLESS OTHERWISE SPECIFIED.

PART NO.	MATERIAL		USE
	BODY	COVER	
NBF-32010	ABS	ABS	INDOOR
NBF-32110	ABS / PC	ABS / PC	INDOOR
NBF-32210	ABS / PC	CLEAR PC	INDOOR
NBF-32310	PBT / PC	PBT / PC	OUTDOOR
NBF-32410	PBT / PC	CLEAR PC	OUTDOOR

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bud Industries:

[NBF-32010](#) [NBF-32110](#) [NBF-32210](#) [NBF-32410](#) [NBF-32310](#)