
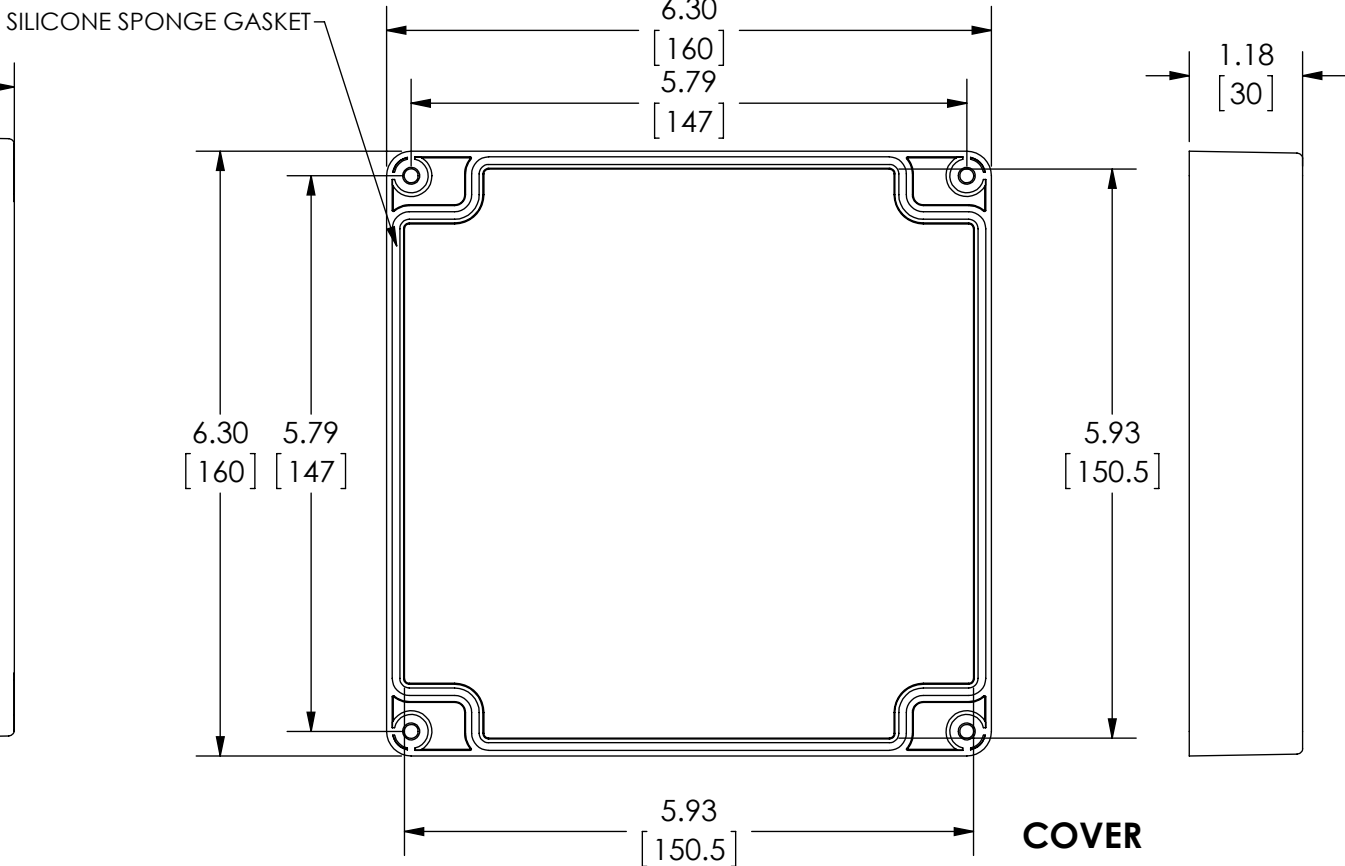
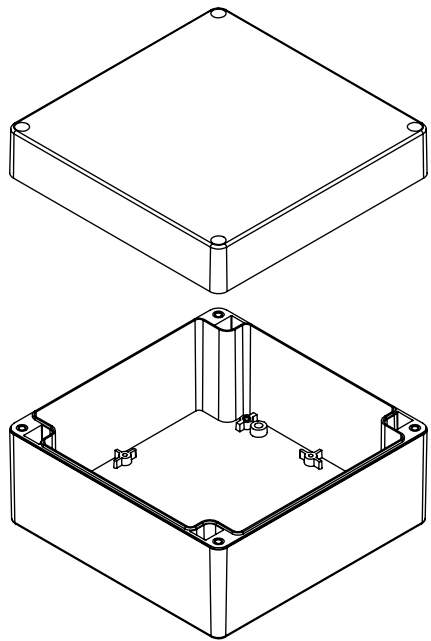
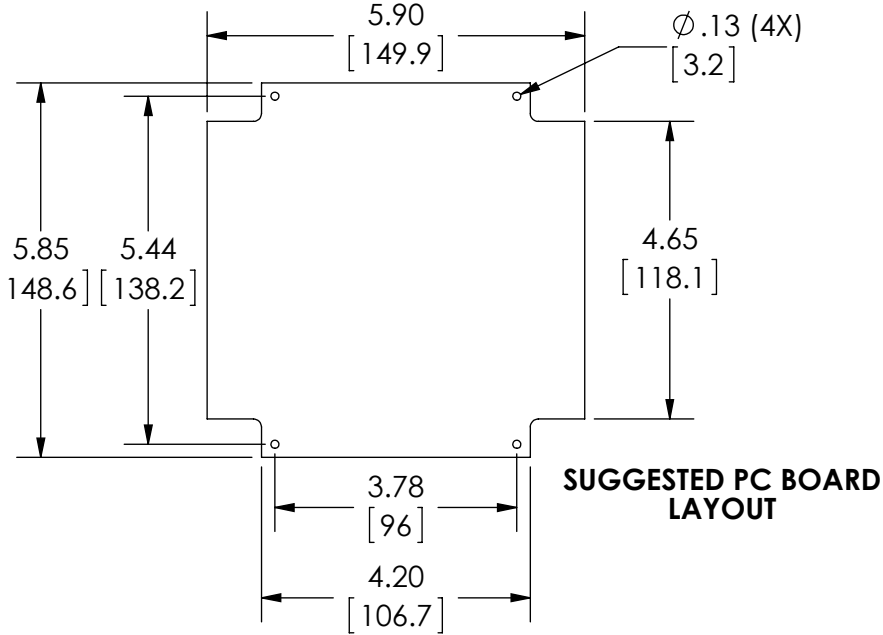


POLYCARBONATE:
LIGHT GRAY AND CLEAR
UL94-HB FLAMMABILITY RATING (UL FILE #E41613)
UV STABILIZED
SERVICE TEMPERATURE RANGE: -40°C TO +120°C

ABS: (FOR INDOOR USE ONLY)
DARK GRAY
UL94-HB FLAMMABILITY RATING (UL FILE #E56070)
SERVICE TEMPERATURE RANGE: -40°C TO +80°C

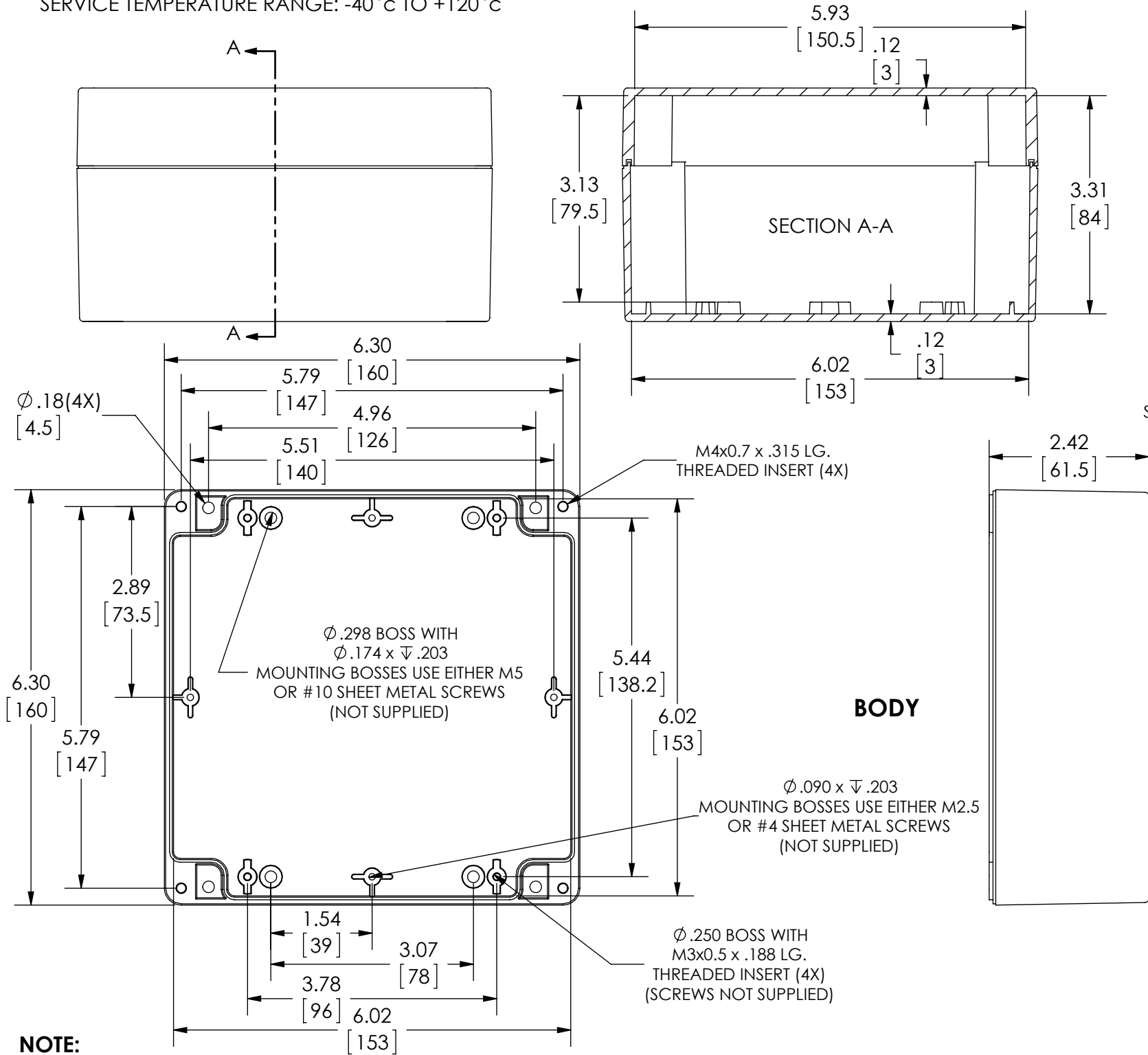

- NOTE:**
- FOUR (4X) M4x0.7 x 20mm LG. STAINLESS STEEL MACHINE SCREWS SUPPLIED FOR ASSEMBLY
 - COVER MOUNTING SCREWS RECOMMENDED TORQUE: 8 IN./LB.
 - ALL DIMENSIONS HAVE +/- .039[+/-1] TOLERANCE
 - ALL OUTSIDE AND INSIDE DRAFT ANGLE: 1°

OPTIONAL ACCESSORIES:
PNX-91438 - OPTIONAL PANEL

NEMA 1,2,3,4,4X,12, AND 13 ENCLOSURE SPECIFICATIONS
DESIGNED TO IP65 OF IEC 529
UL LISTED

PART NUMBER	MATERIAL	BODY / COVER
PN-1339	LIGHT GRAY POLYCARBONATE	BODY & COVER
PN-1339-C	LIGHT GRAY PC	BODY / CLEAR PC COVER
PN-1339-DG	DARK GRAY HIGH-IMPACT ABS	BODY & COVER

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Bud Industries:](#)

[PN-1339-C](#) [PN-1339-DG](#) [PN-1339](#)