



PowerSSO-36 to DIP-40 SMT Adapter (0.5 mm pitch, 10.35 x 7.5 mm body)

REF.	DIMENSIONS					
	mm			inches		
	MIN.	TYP.	MAX.	MIN.	TYP.	MAX.
A		7.80				
B		1.70				
C		0.30				
B2		4.70				
C2		5.50				
D		0.20				
D2		1.55				
E		0.50				
F					0.600	
G					0.100	
H					0.025	

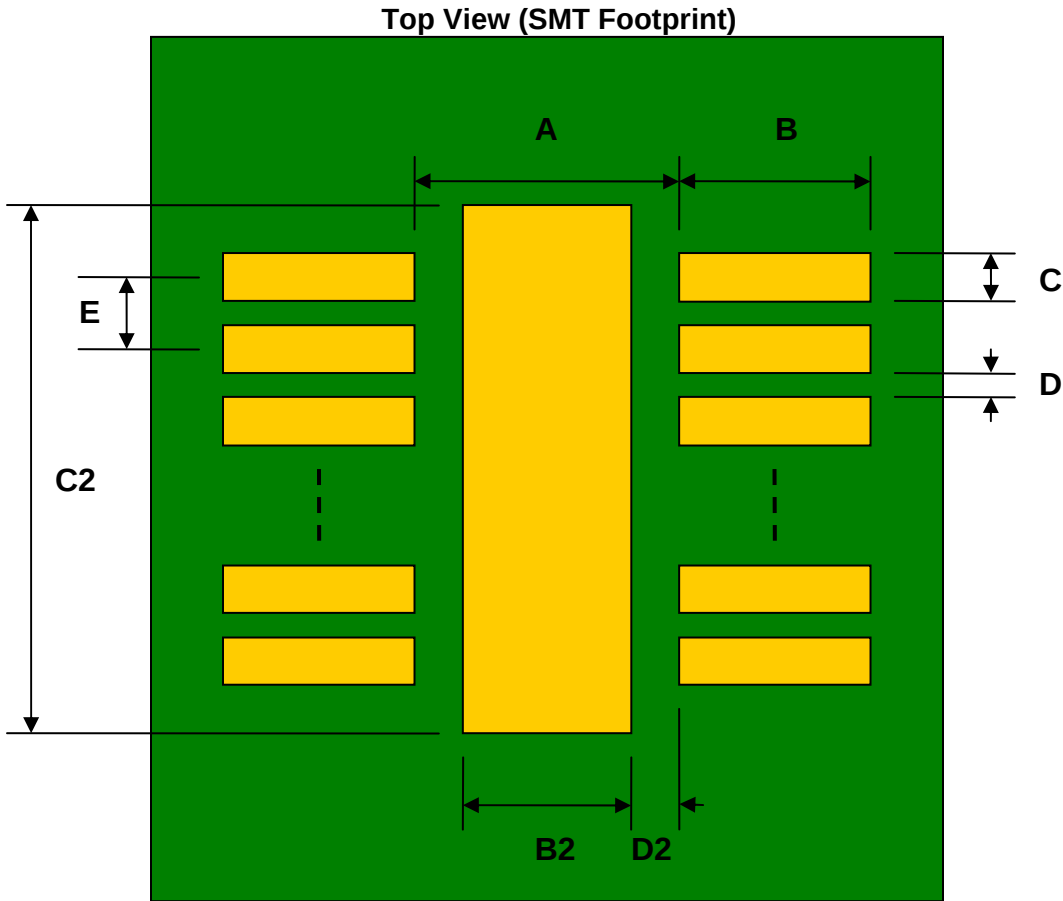


(Representative drawing only - not to scale)

Bottom View (DIP Pins)

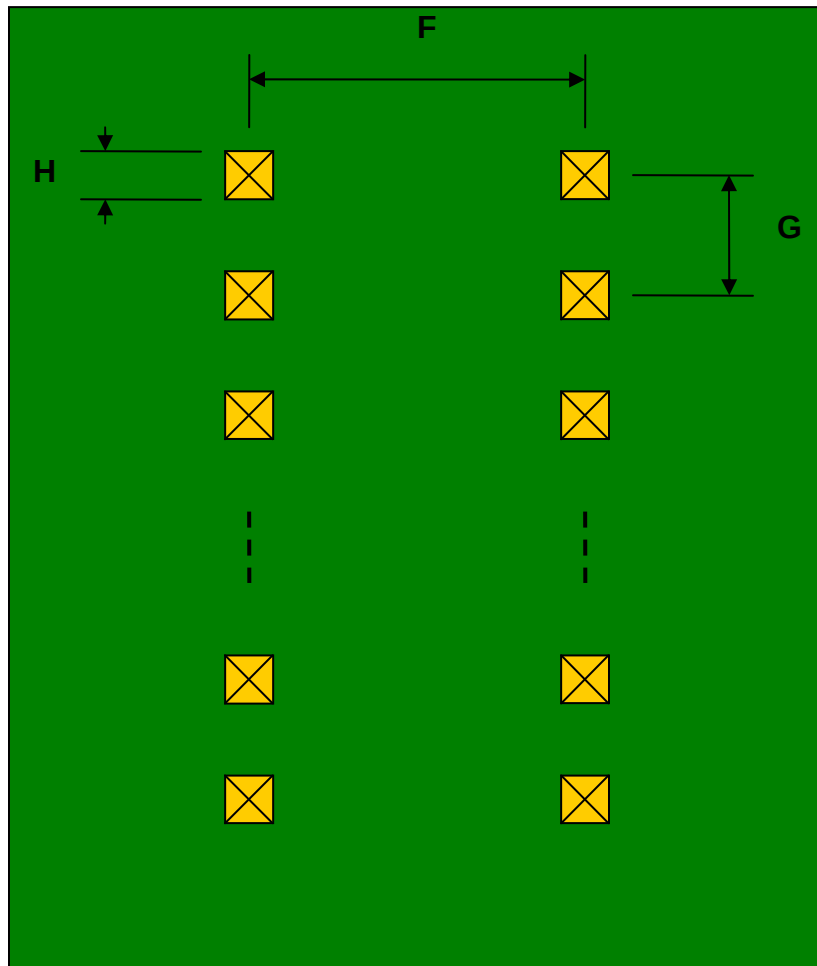

(Representative drawing only - not to scale)

Side View (DIP Pins)

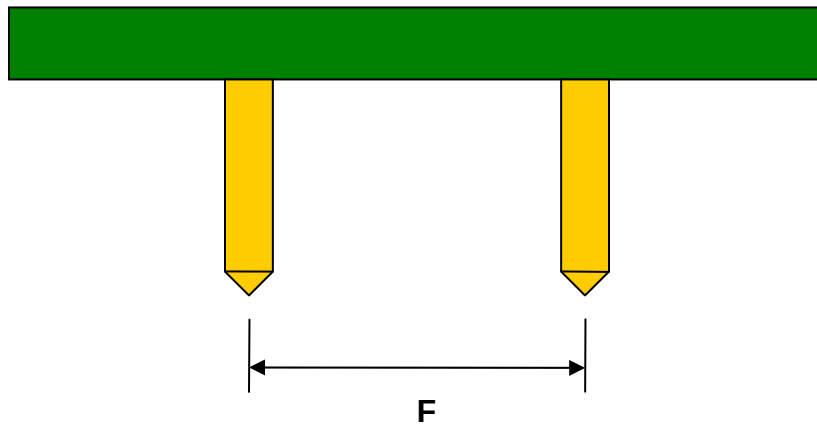

(Representative drawing only - not to scale)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Chip Quik:](#)

[IPC0141](#)