

**Customer Part:**
**Description**

- Standard 7 x 5mm SMD crystal
- 4 pad (metal lid)
  - A ceramic package with a seam sealed metal lid, hermetically sealed. 4 pad device metal lid.
- Model 12SMX-B
- Model Issue number 14

**Frequency Parameters**

- Frequency 14.74560MHz
- Frequency Tolerance  $\pm 50.00$ ppm
- Frequency Stability  $\pm 50.00$ ppm
- Operating Temperature Range -20.00 to 70.00°C
- Overtone Order Fundamental
- Ageing  $\pm 5$ ppm per year max

**Electrical Parameters**

- Load Capacitance 16.00pF
- Shunt Capacitance 7pF max
- Drive Level 100 $\mu$ W max
- ESR 60.00 $\Omega$  max

**Environmental Parameters**

- Storage Temperature Range: -40 to 125°C

**Manufacturing Details**

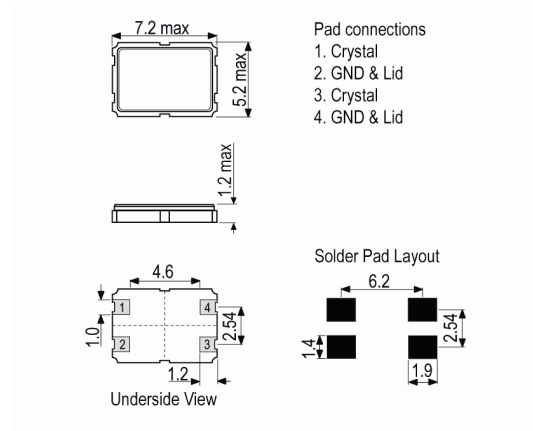
- RoHS Terminations NiAu
- RoHS Reflow Temp 260degC 10s

**Compliance**

- RoHS Status (2015/863/EU) Compliant
- REACH Status Compliant
- MSL Rating (JDEC-STD-033): Not Applicable

**Packaging Details**

- Pack Style: Reel Tape & reel in accordance with EIA-481-D  
Pack Size: 1,000
- *Alternative packing option available*


**Outline (mm)**

**Sales Office Contact Details:**

UK: +44 (0)1460 270200

USA: +1.760 668 8935

 Email: [info@iqdfrequencyproducts.com](mailto:info@iqdfrequencyproducts.com)

 Web: [www.iqdfrequencyproducts.com](http://www.iqdfrequencyproducts.com)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[IQD Frequency Products:](#)

[LFXTAL020965Reel](#)