
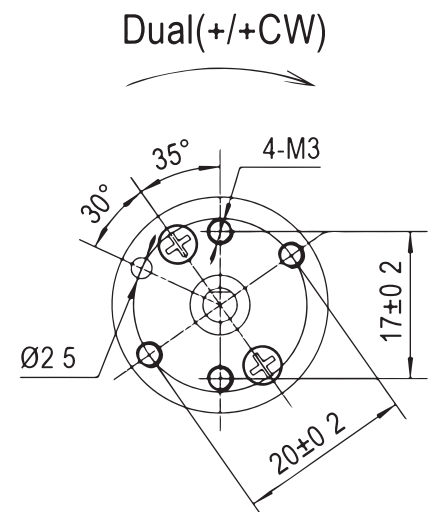


124 RPM DC Metal Gear Motor Part No.: LS-00086

Specifications:

Gear Ratio	1:78
Rated Voltage	12
Free-load Speed	121±12%
Free-load Current	150 Max
Rated Speed	91±12%
Rated Current	1800 Max
Rated Torque	1.5
Stall Current	2800 Max
Max Momentary Tolerance Torque	5 Max
Stall allowed or not	NO
Direction	CCW

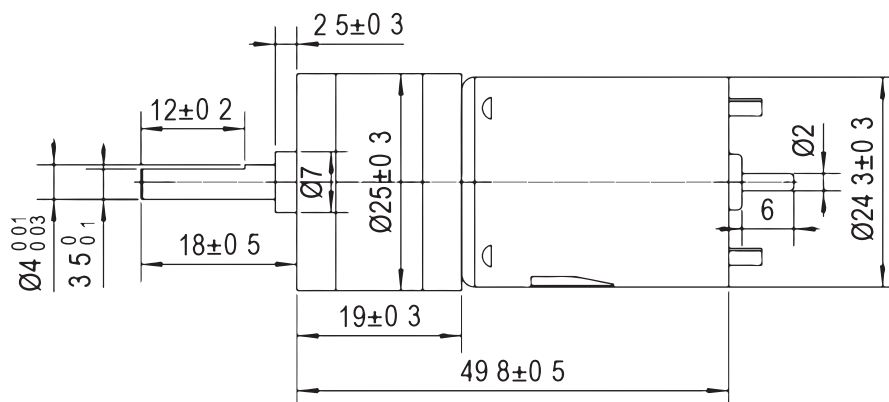

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[OSEPP Electronics:](#)

[LS-00086](#)