

Basler Accessories



Technical Specification

CABLE USB 3.0, MICRO-B 90° A1 SL/A

Order Numbers

2000035994

2000035995

2000036369

Document Number: DG001589

Version: 01 Language: 000 (English)

Release Date: 14 December 2015

Contacting Basler Support Worldwide

Europe, Middle East, Africa

Basler AG
An der Strusbek 60–62
22926 Ahrensburg
Germany

Tel. +49 4102 463 515

Fax +49 4102 463 599

support.europe@baslerweb.com

The Americas

Basler, Inc.
855 Springdale Drive, Suite 203
Exton, PA 19341
USA

Tel. +1 610 280 0171

Fax +1 610 280 7608

support.usa@baslerweb.com

Asia-Pacific

Basler Asia Pte. Ltd.
35 Marsiling Industrial Estate Road 3
#05–06
Singapore 739257

Tel. +65 6367 1355

Fax +65 6367 1255


support.asia@baslerweb.com

www.baslerweb.com

**All material in this publication is subject to change without notice and is copyright
Basler AG.**

Order Number	Description	Applicable Cameras
2000036369	Data cable USB 3.0, Type A plug to Micro-B plug with screw lock, 90° angled, 1 m	ace USB 3.0
2000035994	Data cable USB 3.0, Type A plug to Micro-B plug with screw lock, 90° angled, 3 m	ace USB 3.0
2000035995	Data cable USB 3.0, Type A plug to Micro-B plug with screw lock, 90° angled, 5 m	ace USB 3.0

Table 1: Cable Types

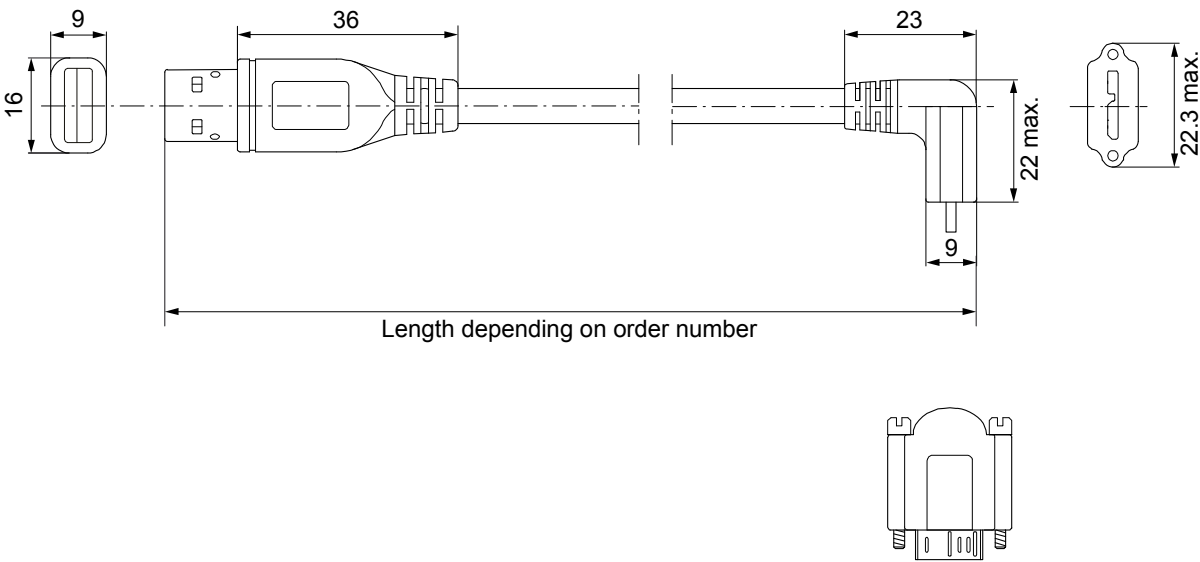

Dimensions in mm

Fig. 1: Cable Overview

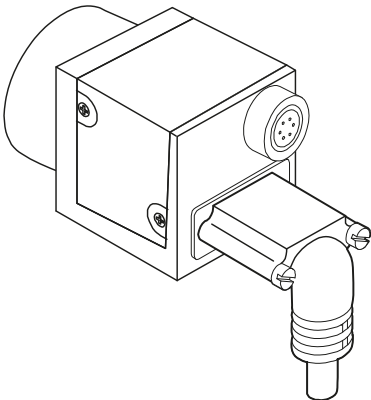


Fig. 2: Angled Cable Plug Connected to ace Camera

Transfer Rates

	2000036369	2000035994	2000035995
USB 2.0	480 Mbps		
USB 3.0	5 Gbps		

Table 2: Transfer Rates

Physical Specifications

	2000036369	2000035994	2000035995
Camera-Side Connector	Micro-B with screw lock, USB3 Vision-compliant		
Host-Side Connector	Type A connector, USB-IF-compliant		
Cable Diameter	6.5 mm max.		
Minimum Bending Radius	65 mm (10 x cable diameter), fixed installation		
Minimum Number of Bending Cycles	None (fixed installation only)		
Suitable for Drag Chain Applications	No		
Suitable for Robotics Applications	No		

Table 3: Physical Specifications

Electrical Specifications

	2000036369	2000035994	2000035995
Nominal Operating Voltage	See camera user's manual		
Maximum Operating Voltage	See camera user's manual		

Table 4: Electrical Specifications

Environmental Specifications

	2000036369	2000035994	2000035995
Operating Temperature	+80 °C max. (not moving)		

Table 5: Environmental Specifications

General Information

	2000036369	2000035994	2000035995
RoHS Compliance	Yes		
CE Conformity	Yes (RoHS compliance)		
UL Conformity	Yes		
Warranty	1 year		

Table 6: General Information



The cables are intended for use with the cameras specified in [Table 1](#) only.



When connecting the cable to the camera, consider that the position of the camera's USB 3.0 connector defines the direction the cable is guided within your installation.

Read the camera user's manual including the safety warnings before connecting the cable to the camera. The user's manual also contains further information about pin assignments, power requirements, as well as comprehensive information about installing and using the camera.

You can download the user's manual and related documents for your camera free of charge from the Basler website: www.baslerweb.com.

Revision History

Doc. ID Number	Date	Changes
DG00158901000	14 Dec 2015	Initial release of this document.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Basler:

[2000036369](#) [2000035995](#) [2000035994](#)