

# Product data sheet

Specifications

SQUARE D



Power Relay, Type C, 2 HP, 30A resistive at 300 VAC, DPST, 2 normally open contacts, 480 VAC coil

8501CO7V29

Product availability: Stock - Normally stocked in distribution facility

## Main

product range	Power Relay 8501C
product type	Power relay
short name	type C
[In] rated line current	30 A
device application	Suited for controlling small single phase motors and other light loads
switch function	DPST
contact composition	2 NO
[Uc] control circuit voltage	480 V AC 50/60 Hz
horsepower rating	2.0 hp
maximum switching voltage	600 V AC

## Complementary

class number	8501
phase	1 phase
terminal connects	Screw clamp terminal
wire range	AWG 10 copper
terminal tightening torque	11...15 lbf.in (1.2...1.7 N.m)
coil burden	10 VA
mounting	Panel mounting

## Environment

ambient temperature range - operational	-30...50 °C (-22...122 °F)
product certifications	UL listed file E78351 CCN NLDX CSA CE
height	2.43 in (61.72 mm)
width	2.5 in (63.5 mm)
depth	2.25 in (57.15 mm)

## Ordering and shipping details

Category	US10CP221131
Discount Schedule	0CP2

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

<b>GTIN</b>	785901059592
<b>Returnability</b>	Yes
<b>Country of origin</b>	CN

## Packing Units

<b>Unit Type of Package 1</b>	PCE
<b>Nbr. of units in pkg.</b>	1
<b>Package 1 Height</b>	2.30 in (5.842 cm)
<b>Package 1 Width</b>	2.50 in (6.35 cm)
<b>Package 1 Length</b>	2.50 in (6.35 cm)
<b>Package weight(Lbs)</b>	9.600 oz (272.155 g)

## Contractual warranty

<b>Warranty</b>	18 months
-----------------	-----------



## Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

### Environmental footprint

[Environmental Disclosure](#)

[Product Environmental Profile](#)

## Use Better

### Materials and Substances

Packaging made with recycled cardboard

No

Packaging without single use plastic

No

[EU RoHS Directive](#)

Pro-active compliance (Product out of EU RoHS legal scope)

REACH Regulation

[REACH Declaration](#)

California proposition 65

**WARNING:** This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)

## Use Again

### Repack and remanufacture

Circularity Profile

No need of specific recycling operations


Take-back

No

Technical Illustration

Dimensions

---

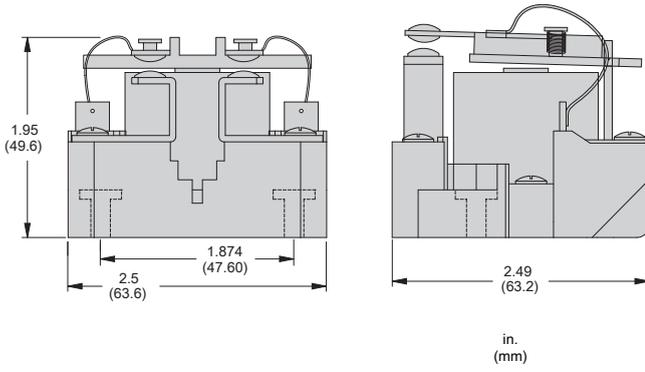


8501CO7  
8501CDO7

All dimensions are approximate.  
Also refer to technical drawings and documentation.

Technical Illustration

Wiring diagram

---

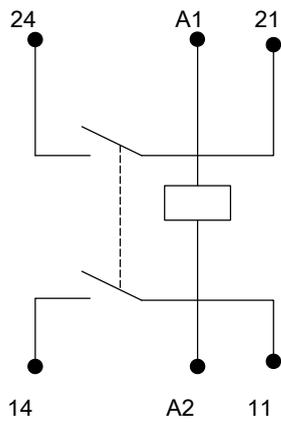

(DPST)  
8501CO7  
8501CDO7